

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130015-0102](#)
Status: **Active**
Overview: [Brad® Mini-Change® Connectors](#)
Description: Mini-Change® C-Size Receptacle with Leads, 1-1/8" - 16 UN-2A Threads, Female (Straight), 19 Poles, 2.0m (6.56') Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Industrial Receptacles
Series [130015](#)
Comments C-Size (1-1/8" - 16 UN-2A)
IP Rating IP67
Overview [Brad® Mini-Change® Connectors](#)
Product Name Mini-Change®
Type Single Ended (pigtail)
UPC 78678847261

Physical
Coupling Type External Thread
Gender Female
Keyway Single
Length 2.0m
Material - Component Gray Anodized Aluminum
Mounting Thread Size PG16
Net Weight 270.780/g
Orientation Straight
Panel Mount Back, Front
Poles 19
Temperature Range - Operating -20°C to +80°C
Wire Size AWG 18, 22
Wire/Cable Type N/A

Electrical
Current - Maximum per Contact 2A
Voltage - Maximum 300V AC/DC

Material Info
Old Part Number 3R3N30E80M020

Reference - Drawing Numbers
Sales Drawing SD-130015-008

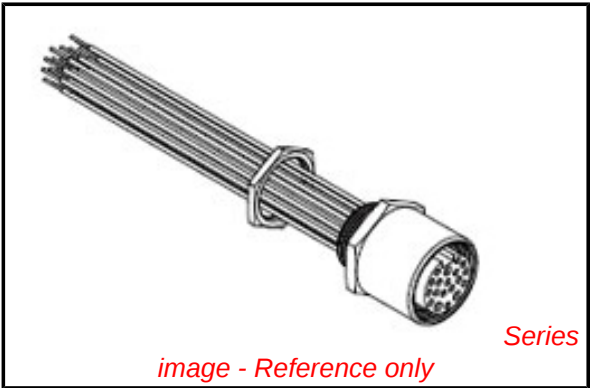

EU RoHS
RoHS Compliant by Exemption
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS

Pb

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[130015Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION