

## 压接插针 - SF-10KP004 - 1607355

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



压接插针，车削，单个插针，触点直径: 1 mm，压接范围: 0.14 mm<sup>2</sup> ... 0.5 mm<sup>2</sup>


根据接线区域，图示可能有所不同

### 优势

- ✓ 压接连接：防振和耐高温组装
- ✓ 抗拉扯
- ✓ 接触电阻低
- ✓ 轻松监控生产



### 关键商业数据

包装单位	100 STK
最小订货量	100 STK
GTIN	 4 046356 174831
GTIN	4046356174831
海关税则号	8536901900
Sales Key	ABREBC

### 技术数据

#### 概述

触点类型	车削
触点直径	1 mm
插针类型	针脚
连接方式	压接
插拔次数	100
绞线最小接线容量	0.14 mm <sup>2</sup>
绞线最大接线容量	0.5 mm <sup>2</sup>
插针材料	铜锌镀层
接点表面	镀镍 (Ni)，带有金覆层 (Au)

# 压接插针 - SF-10KP004 - 1607355


## 技术数据

### Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	环保使用期限 = 50
	更多有害物质的详情，请参考“下载区”内的“制造商声明”

## 产品图

尺寸图

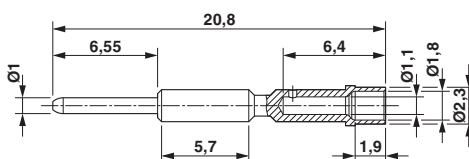

## 分类

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27261200
eCl@ss 6.0	27261200
eCl@ss 7.0	27440204
eCl@ss 8.0	27440204
eCl@ss 9.0	27440204

### ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC000796
ETIM 5.0	EC000796
ETIM 6.0	EC000796

### UNSPSC

UNSPSC 6.01	43172015
UNSPSC 7.0901	43201404
UNSPSC 11	43172015
UNSPSC 12.01	43201404
UNSPSC 13.2	39121522

## 认证

### 认证

## 压接插针 - SF-10KP004 - 1607355

### 认证

---

认证


EAC

---

防爆认证

---

### 认证详情

EAC		B.01742
-----	---	---------

### 附件

附件

压接工具

带数码显示屏的压线钳 - SF-Z0025 - 1607452



压线钳，适用于 $\varnothing 1.0 \text{ mm}$  /  $\varnothing 1.6 \text{ mm}$  /  $\varnothing 2 \text{ mm}$  /  $\varnothing 3.6 \text{ mm}$ 的车削压接插针，绞线横截面积 $0.08 \text{ mm}^2 \dots 6 \text{ mm}^2$

---

带数码显示屏的压线钳 - SF-Z0054 - 1615585



压线钳，适用于 $\varnothing 0.6 \text{ mm}$  /  $\varnothing 0.8 \text{ mm}$  /  $\varnothing 1 \text{ mm}$  /  $\varnothing 2 \text{ mm}$ 的车削压接插针，绞线横截面积 $0.06 \text{ mm}^2 \dots 2.5 \text{ mm}^2$

---