









Durasleeve® Wire marker solution

The DURASLEEVE® markers solution consists of two components: a transparent tube (carrier) with a label pocket and an insert to slide into this pocket. Your legend is at all times protected by the tube and can easily be replaced. The inserts are available in two versions, a standard and a rigidized version. Each insert has its dedicated carrier.

Durasleeve Inserts

- **B-7596** Standard white vinyl tag
- **B-7597** Standard polyethylene insert

Order Reference	Diagram	Sleeves Per Roll	Sleeve Dimensions	
			Width (mm)	Height (mm)
PTDSU-10-7597		1 500	10.00	4.20
PTDSU-10-7597-YL		1 500	10.00	4.20
PTDSU-15-7596		2500	15.00	4.20
PTDSU-15-7596-YL		2500	15.00	4.20
PTDSU-15-7597		1 500	15.00	4.20
PTDSU-15-7597-YL		1 500	15.00	4.20
PTDSU-30-7596		2500	30.00	4.10
PTDSU-30-7596-YL		2500	30.00	4.10
PTDSU-30-7597		1 500	30.00	4.10
PTDSU-30-7597-YL		1 500	30.00	4.10

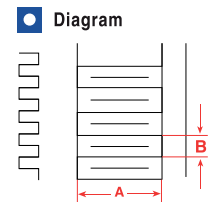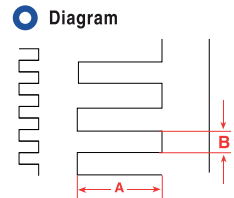

Durasleeve Carriers

Carriers for DuraSleeve insert

Order Reference	Carrier Width (mm)	Wire O.D. (mm)	Carriers per Box
DMC-1.3/3-15	15.00	1.30 – 3.00	1 000
DMC-1.3/3-30	30.00		500
DMC-2.5/5-15	15.00	2.50 – 5.00	1 000
DMC-2.5/5-30	30.00		500
DMC-4/10-15	15.00	4.00 – 10.00	500
DMC-4/10-30	30.00		200
DMC-8/16-15	15.00	8.00 – 16.00	500
DMC-8/16-30	30.00		200



Rigid Durasleeve Inserts

- **B-7696** Rigid vinyl tag

Order Reference	Labels per roll	Dimensions – mm	
		A	B
PTLRDS-10x4,4-7696	2500	10.00	4.40
PTLRDS-12x4,4-7696	2500	12.00	4.40
PTLRDS-16x4,4-7696	2500	16.00	4.40
PTLRDS-23x4,4-7696	2500	23.00	4.40
PTLRDS-30x4,4-7696	2500	30.00	4.40



Ademark Tag Carrier

The carriers are available in width: 10, 12, 16, 23 or 30 mm

Model	Wire O.D. (mm)	Carriers per Box
0	1.30/2.00 mm	2000
1	1.80/2.50 mm	2000
2	2.50/4.00 mm	2000
3	4.00/6.50 mm	1000
4	6.00/10.00 mm	1000
5	9.00/15.00 mm	1000
6	15.00/24.00 mm	500

