


**PTSM 0,5/ 6-HH-2,5-SMD R44**

Order No.: 1778803



Header, Nominal current: 6 A, Rated voltage (III/2): 160 V, Number of positions: 6, Pitch: 2.5 mm, Color: Black, Contact surface: Tin, Assembly: SMD/THT/THR

**Commercial data**

EAN	 4 046356 530019
Note	Made-to-order
Pack	600 Pcs.
Customs tariff	85369010
Product key	AACMBA
Catalog page information	Page 57 (CC-2011)

**Product notes**

WEEE/RoHS-compliant since:  
09/17/2009



<http://www.download.phoenixcontact.com>  
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

**Technical data****Dimensions / positions**

Length	7.5 mm
Pitch	2.5 mm
Dimension a	12.5 mm
Number of positions	6

Pin spacing	2.50 mm
<b>Technical data</b>	
Range of articles	PTSM 0,5/...-HH-SMD
Insulating material group	IIIa
Rated surge voltage (III/3)	2.5 kV
Rated surge voltage (III/2)	2.5 kV
Rated surge voltage (II/2)	2.5 kV
Rated voltage (III/2)	160 V
Rated voltage (II/2)	160 V
Connection in acc. with standard	EN-VDE
Nominal current $I_N$	6 A
Nominal voltage $U_N$	50 V
Maximum load current	6 A
Insulating material	LCP
Inflammability class according to UL 94	V0
Color	Black
Nominal voltage, UL/CUL Use Group B	150 V
Nominal current, UL/CUL Use Group B	6 A

### Certificates / Approvals




Certification


CUL, UL

## Drawings

### Drilling plan/solder pad geometry

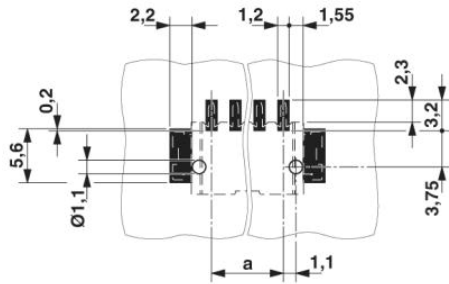

### Dimensioned drawing

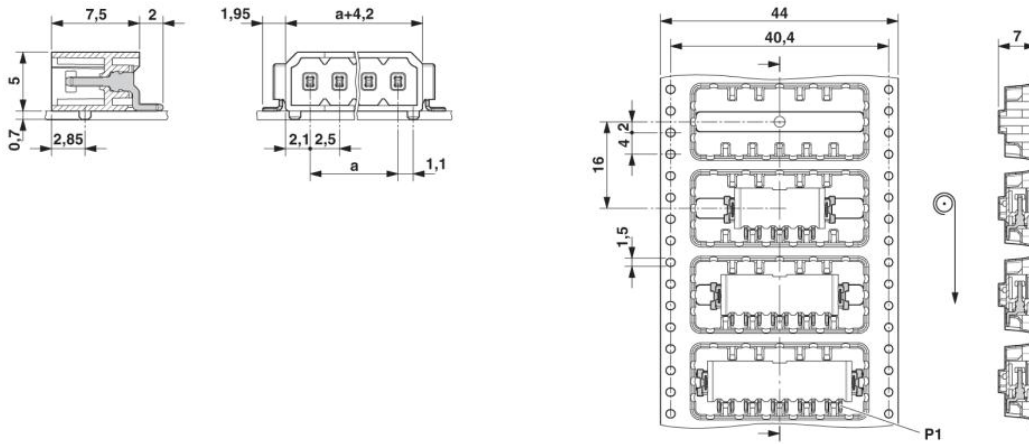

---

**Address**

PHOENIX CONTACT Inc., USA  
586 Fulling Mill Road  
Middletown, PA 17057, USA  
Phone (800) 888-7388  
Fax (717) 944-1625  
<http://www.phoenixcon.com>



© 2012 Phoenix Contact  
Technical modifications reserved;