


# Datasheet

## Pitch 72 Way 2 Row Straight PCB Header

RS Stock number [547-3188](#)

Dimensions: (mm)

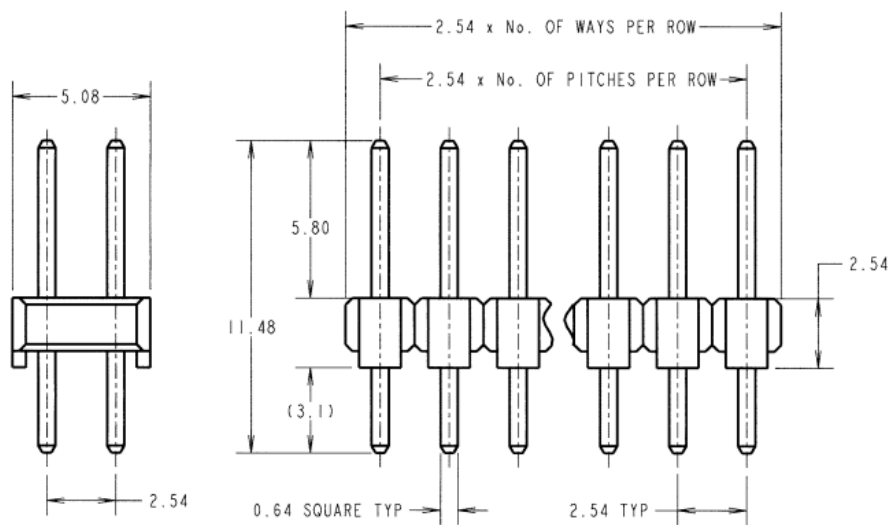

# Specification

<b>Material</b>	<ul style="list-style-type: none"> <li>Moulding: 0.5 &amp; 0.6 = Glass- Filled Polyester UL94V-0, Black 45 &amp; 46 = High temp Nylon UL94V-0, Black</li> <li>Pins: Brass</li> <li>Finish: <ul style="list-style-type: none"> <li>05 = gold</li> <li>06 = Tin/Lead</li> <li>45 = Gold</li> <li>46 = 100% Tin</li> </ul> </li> </ul>
<b>Electrical</b>	<p>Current Rating: 3A Max  Contact Resistance: 25m Ω Max (gold), 50 operations (tin)  Dielectric Strength: 750V AC/DC</p>
<b>Mechanical</b>	<p>Durability: 300 operations (gold) 50 operations (tin)</p>
<b>Environmental</b>	<p>Temperature Range: -40°C to +105 °C</p>