

PTPM 0,4/ 6-P-2,5

Order No.: 1780545



<http://eshop.phoenixcontact.co.uk/phoenix/treeViewClick.do?UID=1780545>

Plug component, Nominal current: 4 A, Rated voltage (III/2): 125 V,
Number of positions: 6, Pitch: 2.5 mm, Color: black, Metal surface: Sn

Commercial data

EAN	4046356536196
Pack	100
Weight/Piece	2.84 g
Country of Origin	US
Catalog page information	Page 183 (NTK-2010)

Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation at <http://www.download.phoenixcontact.com>. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

Dimensions / positions

Pitch	2.5 mm
Dimension a	12.5 mm
Number of positions	6

Technical data

Range of articles	PTPM 0,4/ -P
Insulating material group	III
Rated surge voltage (III/3)	2.5 kV
Rated surge voltage (III/2)	2.5 kV
Rated surge voltage (II/2)	2.5 kV


Rated voltage (III/2)	125 V
Rated voltage (II/2)	125 V
Connection in acc. with standard	EN-VDE
Nominal current I_N	4 A
Nominal voltage U_N	32 V
Nominal cross section	0.34 mm ²
Maximum load current	4 A
Insulating material	PA/PC
Inflammability class acc. to UL 94	V0/V2

Connection data

Conductor cross section stranded min.	0.25 mm ²
Conductor cross section stranded max.	0.34 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	22

Drawings

Dimensioned drawing

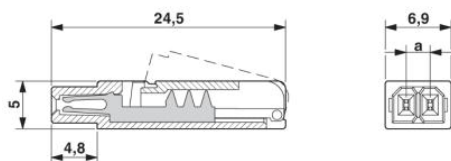

Address

PHOENIX CONTACT Ltd
Halesfield 13
Telford / Shropshire / TF7 4PG, England
Phone 01952 681 700
Fax 01952 681 799
<http://www.phoenixcontact.co.uk>



Phoenix Contact Ltd.
Technical modifications reserved;