


# PL3 SERIES

## Push & Lever Type



### HOW TO ORDER

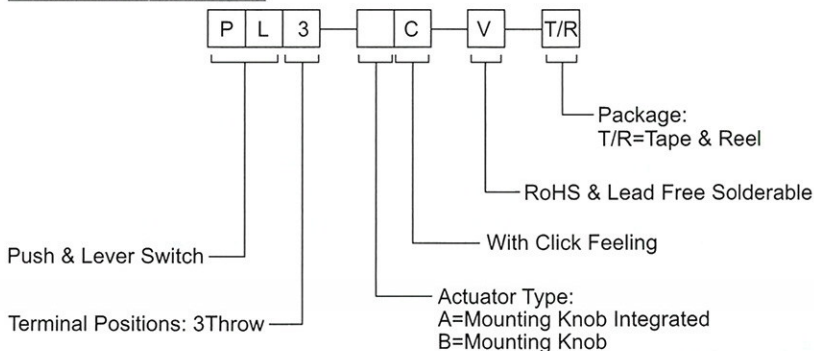

### SPECIFICATION

#### MECHANICAL

Operation Force:  
Center push 200±100gf.  
Lever (CW, CCW) 70±50gf

#### ENVIRONMENTAL

Operation Temperature Range : -10°C to +60°C  
Storage Temperature Range : -30°C to +80°C


#### ELECTRICAL

Electrical Life: 100,000 cycles.  
Rating: 10mA, 5VDC



#### PACKAGE

Tape & Reel: 900 pcs/reel

### CIRCUIT


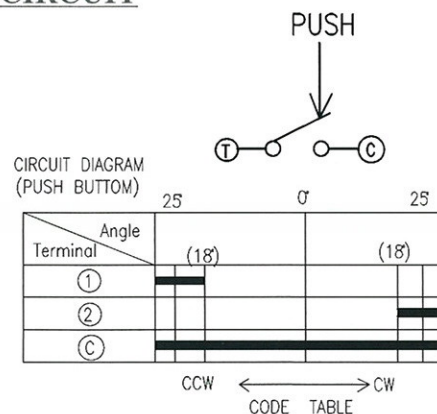


### PL3-AC

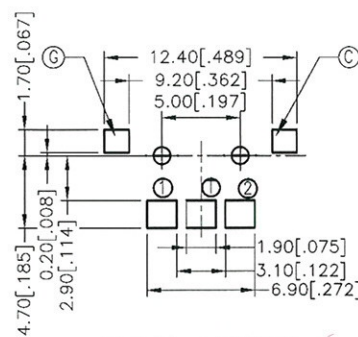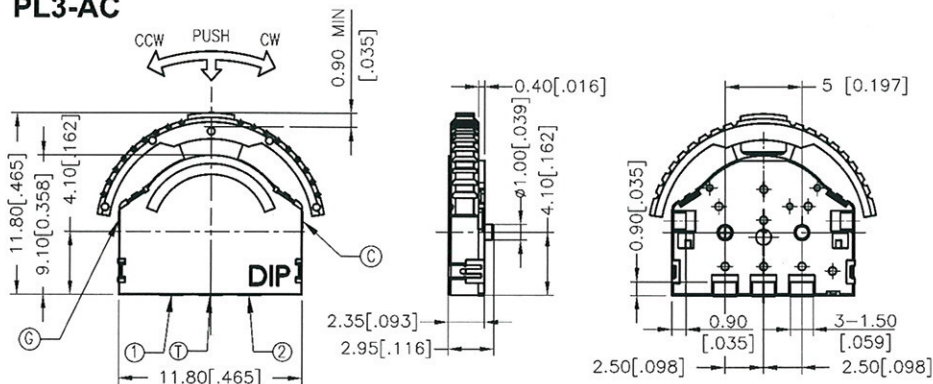

P.C.B. LAYOUT

### PL3-BC

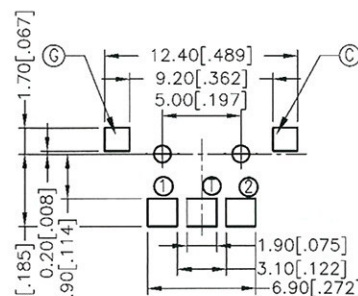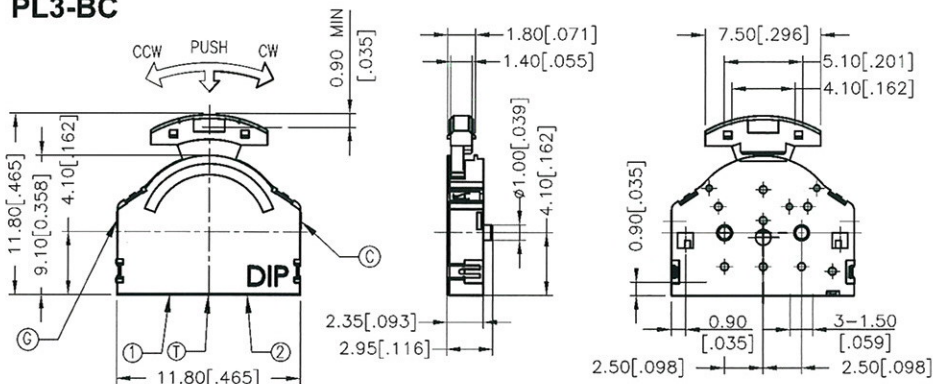

P.C.B. LAYOUT

General Tolerance: ±0.2mm(±0.008")