


Self-aligning ball bearings, cylindrical and tapered bore, cylindrical bore, seal on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
15	35	14	7,41	1,76	0,09	-	14000	0,058	2202 E-2RS1TN9

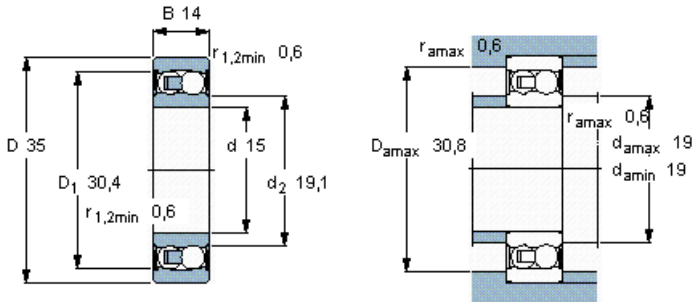

Calculation factors

e 0,33
 Y_1 1,9
 Y_2 3
 Y_0 2