


Spherical roller bearings, cylindrical and tapered bore

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
45	85	28	102	98	10,8	-	2000	0,66	BS2-2209-2CS/VT143 *

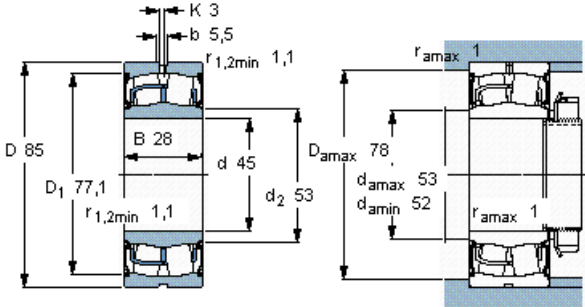

Calculation factors

- e 0,26
- Y_1 2,6
- Y_2 3,9
- Y_0 2,5