


Terminal blocks
spring connection


Standard

DIN 3

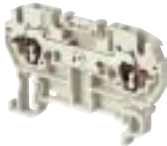

D 2,5/5.2L

Spacing 5 mm +0,05 .198"

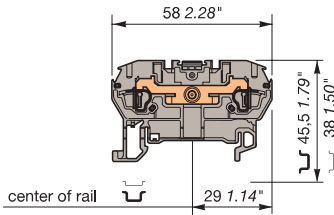

Terminal blocks with 2 springs.

Grey 0290 021.27


Color Type Part numbers

Standard blocks

Orange	D 2,5/5.2L	0290 022.20
Blue	D 2,5/5.N.2L	0290 023.21
Red	D 2,5/5.2L	0290 024.22
Black	D 2,5/5.2L	0290 026.24
Yellow	D 2,5/5.2L	0290 027.25
Green	D 2,5/5.2L	0290 028.06



Accessories

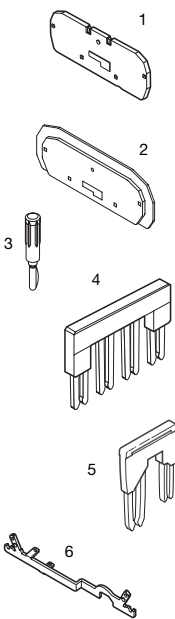

- 1 End section grey
- 2 Separator orange
- 3 Test plug black
- 4 Jumper bar orange IP 20 - 24 A
- 5 Jumper bar orange For blocks of different spacing
 - spacing 5 and 6 mm IP 20 - 24 A
 - spacing 5 and 8 mm IP 20 - 24 A
 - spacing 5 and 10 mm IP 20 - 24 A
- 6 Shielding connector

Type Part numbers

FED5.2L	V0	th. 2,5 mm	0291 061.24
FED5.2L	V0	th. 2,5 mm	0291 062.25
SCD5.2L	V0	th. 2,5 mm	0291 352.04
FC2	V2	DIA. 2,0 mm	0007 865.26
BJDL5.2	V0	2 poles	0291 102.23
BJDL5.3	V0	3 poles	0291 103.24
BJDL5.4	V0	4 poles	0291 104.25
BJDL5.5	V0	5 poles	0291 105.26
BJDL5.6	V0	6 poles	0291 106.27
BJDL5.7	V0	7 poles	0291 107.20
BJDL5.8	V0	8 poles	0291 108.01
BJDL5.9	V0	9 poles	0291 109.02
BJDL5.10	V0	10 poles	0291 110.26

BJDPL56	(1)	0291 150.06
BJDPL58	(1)	0291 160.00
BJDPL510	(1)	0291 480.22
CBD5.2L	th. 0,5 mm	0291 077.24

End stop	th. 9 mm	BADL	V0	0399 903.02
End stop	th. 9,1 mm	BAM	V2	0103 002.26
End stop	th. 9,1 mm	BAM V0	V0	0199 306.03
Rail	35 x 7,5 x 1	PR3.Z2		0174 300.17
Rail	35 x 15 x 2,3	PR4		0168 500.12
Rail	35 x 15 x 1,5	PR5		0168 700.22

Other end stops, rails and accessories : see section on accessories.

Characteristics

Wire size		
	IEC	UL/CSA
	NFC DIN	
Solid wire	0,12-4 * mm²	26-12 AWG
Stranded wire	0,12-2,5 mm²	26-12 AWG
With isolated ferrule	0,5-2,5 mm²	
Voltage		
Rated	800 V	600 V
Pulse	8 kV	
Pollution degree	3	
Current		
Rated	24 A	15 A
Wire size		
Rated / Gauge	2,5 mm² / A2	12 AWG
Wire strip. length	Recomm. torque	Protection
9,5 mm	3,5 mm	IP20
.37"	.14"	NEMA 1

Notes

The use of some accessories may decrease the block's voltage rating. For more information, consult us.

*Entrelec spring connection terminal blocks comply with IEC 947-1 standard for 2.5 mm² rated wire size. Never the less, our spring terminal blocks can be connected to 4 mm² solid wires.

One wire per spring.
Terminal block body material is UL 94 V0.



R See section on marking method

On top: RC 510 ⑥ or RPC ②⑩
On sides: RC 55 ⑤

(1) End section must be inserted between 2 interconnected blocks.