


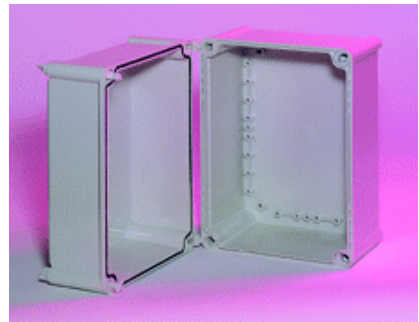

This is a sample photo.

ORDER SYMBOL: SC 3828 18 GII

EL.number **EAN:** 6418074036612
Sweden:
Denmark:
Finland: 3422546


INCLUDING:
Cabinet body, cover, hinges, quick-lock screws, and mounting screws.

APPROVALS:
USA: NEMA 4, 4X, 12; UL 94-V0

EURO: IP 65; UL 94-V0

OTHERS: IEC 529, CE, EEI, SETI 163458-01

FIBOX SOLID SC II

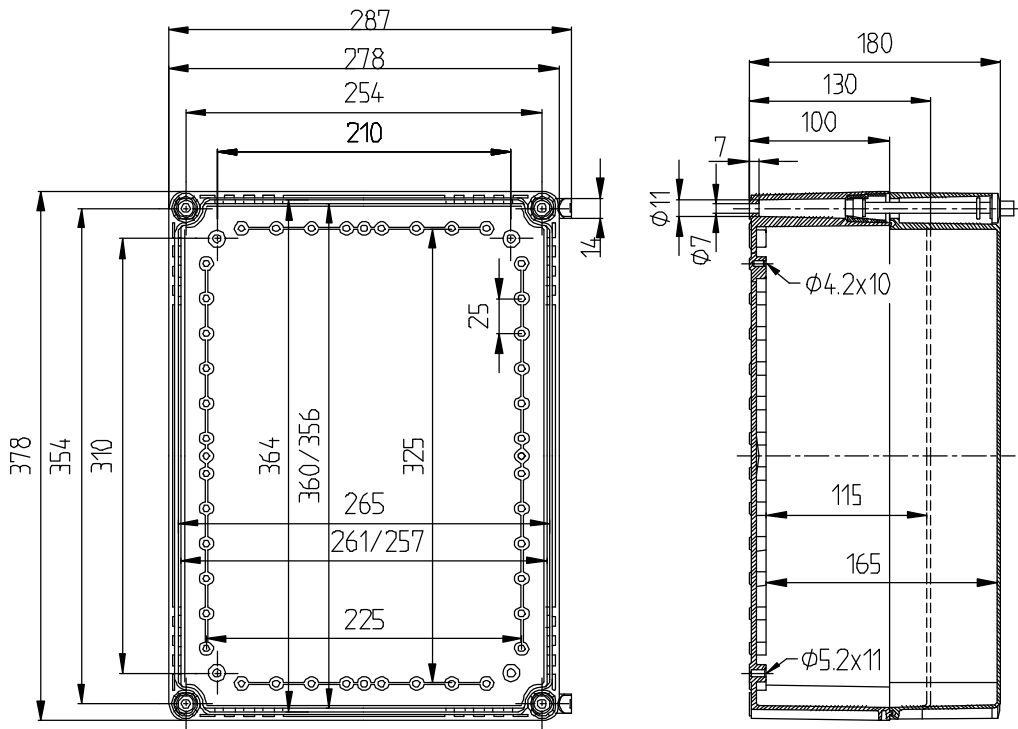

TECHNICAL INFORMATION:

Standard colour: RAL 7035
Ingress protection: IP 65 (IEC 529)
Flame resistance:
Temp.range in cont. use: Max. +80 °C
Temp. range of material: - 40 °C - + 120 °C

ACCESSORIES

DIN-Rail	EKV 12	Earth bar set	MR 26059
DIN-Rail	EKV 14		
DIN-Rail	EKV 22		
DIN-Rail	EKV 24		
DIN-Rail	EKV 32		
DIN-Rail	EKV 34		
Corner plug	MB 10523		
Fastening lug	MB 10674		
Earth bar support	MB 26069		