


MECHANICAL SPECIFICATION

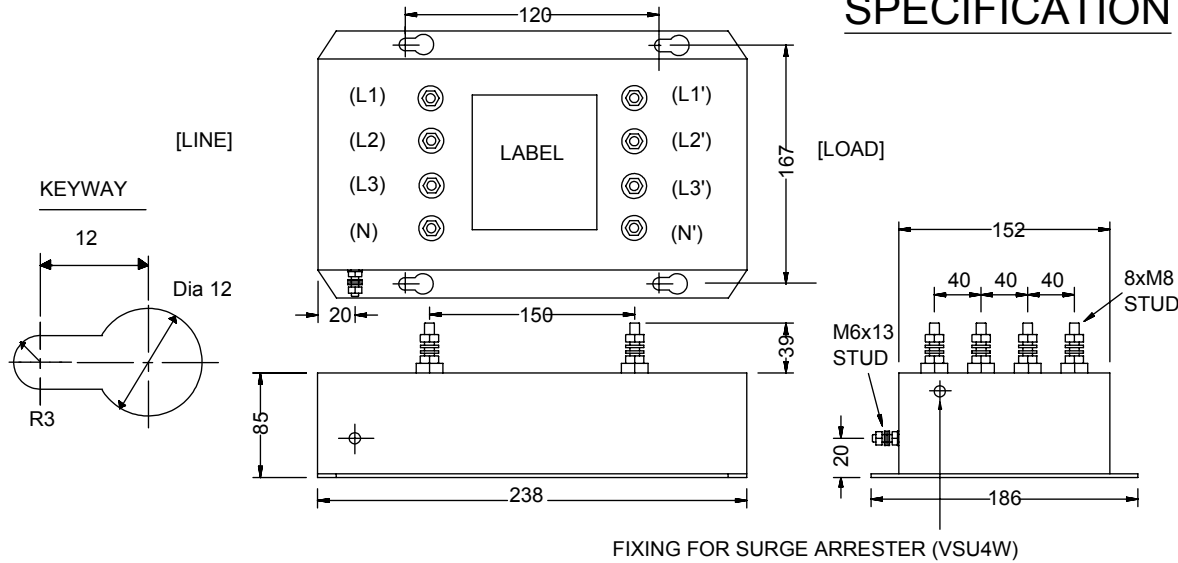

ELECTRICAL SPECIFICATION

RATED VOLTAGE 480/277V
LINE FREQUENCY 50/60Hz
TEMPERATURE RANGE -25 to 85 DegC
TEST VOLTAGE 2.0KV DC
LEAKAGE CURRENT 2.2mA AT 250V 50Hz
WEIGHT 6.35kg

PRODUCT RANGE

TYPE	CURRENT I(RMS) @40°C	INDUCTANCE (L)	RESISTANCE (R) PER WINDING	MINIMUM INSERTION LOSS AT 150 KHZ	
				COMMON MODE	DIFFERENTIAL MODE
IHF470	70A	0.72 mH	0.52 mR	35dB	23dB
IHF4100	100A	0.40 mH	0.30 mR	30dB	18dB

RoHS
2002/95/EC

Compliant