

Flat Cable Connectors SEK

- har-mik®
- D-Sub
- InduCom

Applications



Product details

09 18 550 5803
IDC female connector

Termination	Flat cable insulation displacement
Connector size	50 contacts
IDC strain relief clamp	Without strain relief
Cover	With an open end cover
Centre polarization	With central polarisation
Performance level	AU-0.76•m [30• Inch]
RoHS compliant	Yes

Available Downloads


Title	Format	
Data sheet	PDF	download
CAD data 2D	DXF	download

Further links

3D-Library



Inquiry

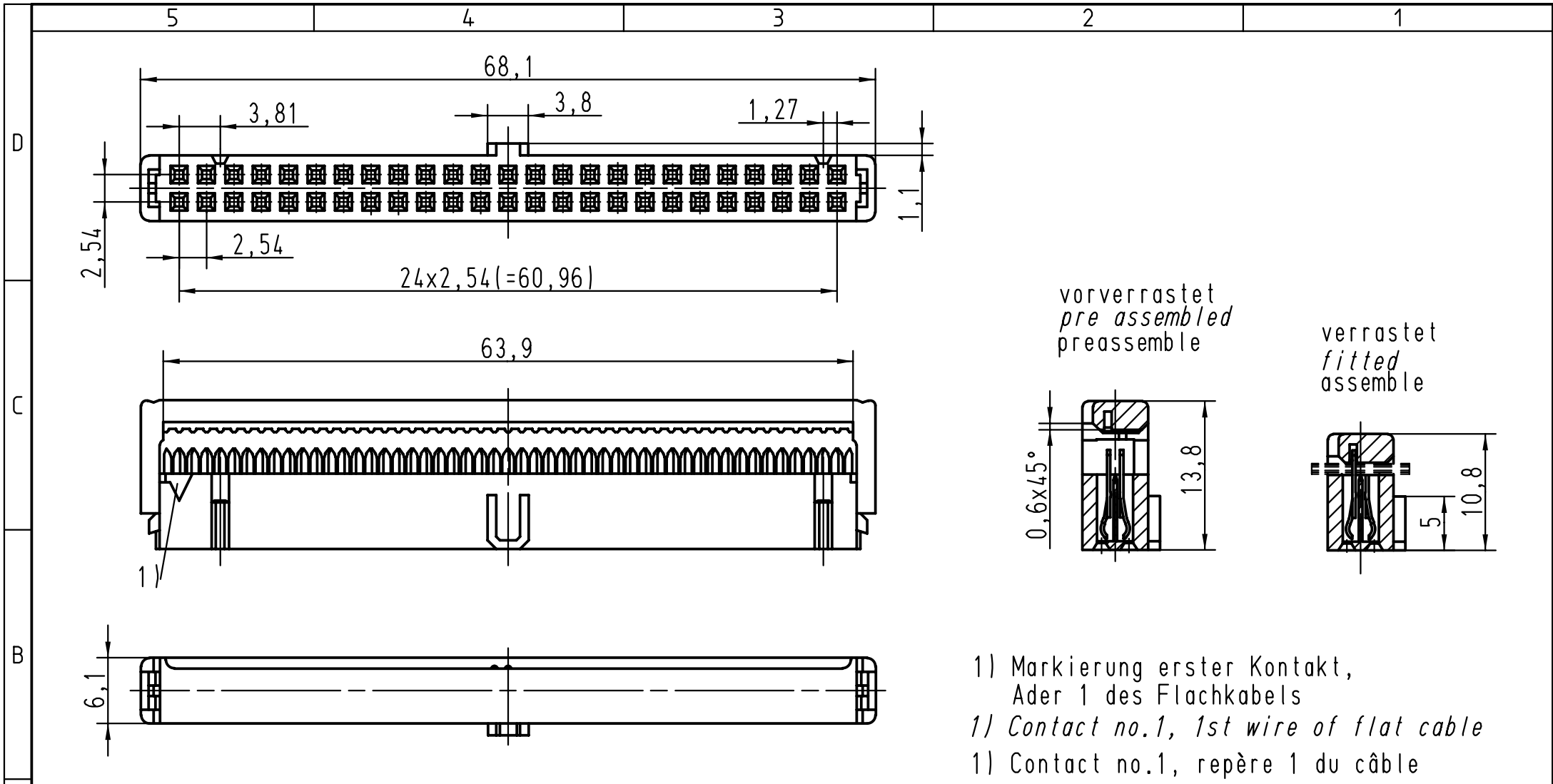

- 1) Markierung erster Kontakt,
Ader 1 des Flachkabels
1) Contact no.1, 1st wire of flat cable
1) Contact no.1, repère 1 du câble

						Techn. Character.				Nicht tolerierte Masse/ <i>Free size tolerances</i>		
A	09185505803	0,76 µm Au					Detail.	01-FEB-00	Th	2:1	SEK 18 Female connector 50 poles with central polarisation cover without cable stop	
	09185506803	2					Insp.	01-FEB-00	JMV			
	09185507803	3					Stand.					
	Bestell-Nr. Part-No. Reference	Anforderungsstufe performance level Niveau de qualite					HARTING EURL F-95972 Paris				TB 0918550X803	Blatt/ page 1/1
						26570	01-FEB-00	JB				
						Mod.	Dat.	Name				