


# Shafts and shaft accessories

## Ordering information

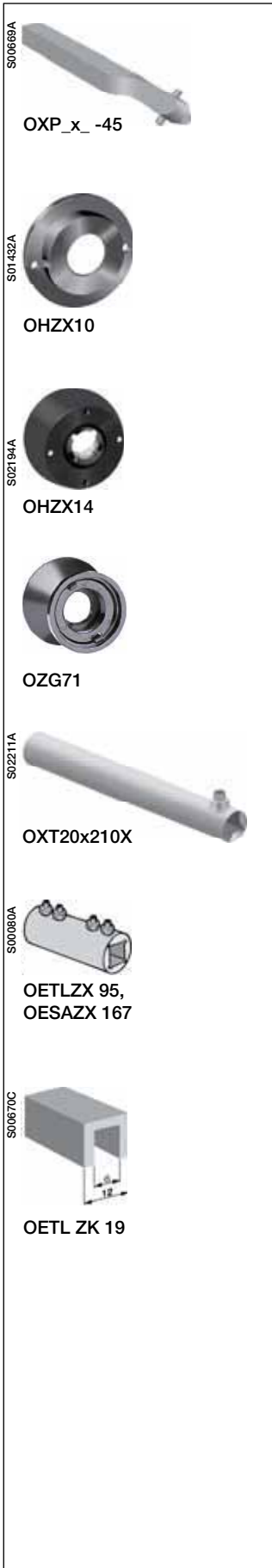

### Shafts

Twisted shafts for pistol type handles, the shaft position is rotated 45 degrees. The type and the ordering numbers are for one piece.

| Shaft length [mm]                                    | H dimension [mm]       | Suitable for switches | Type         | Order number    | Delivery batch [pcs] | Weight/unit [kg] |
|--|------------------------|-----------------------|--------------|-----------------|----------------------|------------------|
| <b>For pistol type handles. Shaft diameter 6 mm.</b> |                        |                       |              |                 |                      |                  |
| 150  | See dimension drawings | OT16...125F           | OXP6X150-45  | 1SCA022294R4400 | 10                   | 0.05             |
| 170  |                        | OT16...125F           | OXP6X170-45  | 1SCA108227R1001 | 10                   | 0.05             |
| 265  |                        | OT16...125F           | OXP6X265-45  | 1SCA108228R1001 | 10                   | 0.08             |
| 400  |                        | OT16...125F           | OXP6X400-45  | 1SCA108229R1001 | 10                   | 0.12             |
| 130  | 109...174              | OT160EV...250         | OXP6X130-45  | 1SCA022355R9110 | 10                   | 0.04             |
| 150  | 129...194              | OT160EV...250         | OXP6X150-45  | 1SCA022294R4400 | 10                   | 0.05             |
| 210  | 189...254              | OT160EV...250         | OXP6X210-45  | 1SCA022294R4230 | 10                   | 0.06             |
| 290  | 269...334              | OT160EV...250         | OXP6X290-45  | 1SCA022304R4290 | 10                   | 0.08             |
| <b>Shaft diameter 12 mm</b>                          |                        |                       |              |                 |                      |                  |
| 250  | 230...310              | OT315...400           | OXP12X250-45 | 1SCA022293R9400 | 1                    | 0.28             |
| 280  | 260...340              | OT315...400           | OXP12X280-45 | 1SCA022382R0800 | 1                    | 0.30             |
| 325  | 305...385              | OT315...400           | OXP12X325-45 | 1SCA022304R4450 | 1                    | 0.36             |
| 395  | 445...525              | OT315...400           | OXP12X395-45 | 1SCA022749R0640 | 1                    | 0.43             |
| 465  | 439...519              | OT315...400           | OXP12X465-45 | 1SCA022423R1770 | 1                    | 0.51             |
| 535  | 515...595              | OT315...400           | OXP12X535-45 | 1SCA022723R2940 | 1                    | 0.59             |
| 250  | 226...355              | OT1000...2500         | OXP12X250-45 | 1SCA022293R9400 | 1                    | 0.28             |
| 280  | 256...385              | OT1000...2500         | OXP12X280-45 | 1SCA022382R0800 | 1                    | 0.30             |
| 325  | 301...430              | OT1000...2500         | OXP12X325-45 | 1SCA022304R4450 | 1                    | 0.36             |
| 395  | 371...500              | OT1000...2500         | OXP12X395-45 | 1SCA022749R0640 | 1                    | 0.43             |
| 465  | 441...570              | OT1000...2500         | OXP12X465-45 | 1SCA022423R1770 | 1                    | 0.51             |
| 535  | 511...640              | OT1000...2500         | OXP12X535-45 | 1SCA022723R2940 | 1                    | 0.59             |
| 325  | 340...535              | OETL3150              | OXP12X325-45 | 1SCA022304R4450 | 1                    | 0.36             |
| 395  | 410...605              | OETL3150              | OXP12X395-45 | 1SCA022749R0640 | 1                    | 0.43             |
| 465  | 480...675              | OETL3150              | OXP12X465-45 | 1SCA022423R1770 | 1                    | 0.51             |
| 535  | 550...745              | OETL3150              | OXP12X535-45 | 1SCA022723R2940 | 1                    | 0.59             |

### Shaft alignment ring

Improves the handle operation if a handle and a shaft have been poorly aligned. The type and the ordering numbers are for one piece.

| Colour   | Suitable for handle | Type   | Order number    | Delivery batch [pcs] | Weight/unit [kg] |
|--|---------------------|--------|-----------------|----------------------|------------------|
| <b>For pistol type handles OH_65...275J6...12.</b> |                     |        |                 |                      |                  |
| Black  |                     | OHZX10 | 1SCA022661R3610 | 10                   | 0.23             |
| <b>For selector type handles OH_1...3</b>          |                     |        |                 |                      |                  |
| Black  |                     | OHZX11 | 1SCA022708R3170 | 10                   | 0.23             |
| <b>For round padlockable handle OZ371P_</b>        |                     |        |                 |                      |                  |
| Black  |                     | OZG71  | 1SCA111686R1001 | 10                   | 0.05             |

### Extension ring for pistol type handles

|       |      |        |                 |   |      |
|-------|------|--------|-----------------|---|------|
| Black | OHB_ | OHZX14 | 1SCA022851R6590 | 1 | 0.06 |
|-------|------|--------|-----------------|---|------|

### Shaft tube for OT1000...2500

For switch-disconnectors with wide phase distance (140 mm or 185 mm) Supporting 12 mm shafts longer than 280 mm

|            |                 |   |     |
|------------|-----------------|---|-----|
| OXT20x210X | 1SCA103684R1001 | 1 | 1.5 |
|------------|-----------------|---|-----|

### Shaft extension socket

For extending the shaft of combination attachment.

| Shaft diameter [mm] | Type      | Order number    | Units/type [pcs] | Weight/unit [kg] |
|---------------------|-----------|-----------------|------------------|------------------|
| 6                   | OESAZX167 | 1SCA022190R1560 | 1                | 0.03             |
| 12                  | OETLZX95  | 1SCA022083R5620 | 1                | 0.04             |

### Adapter for extension socket

The adapter can be placed inside the extension socket OETLZX95.

|   |          |                 |   |      |
|---|----------|-----------------|---|------|
| 6 | OETLZK19 | 1SCA022093R1850 | 1 | 0.02 |
|---|----------|-----------------|---|------|