
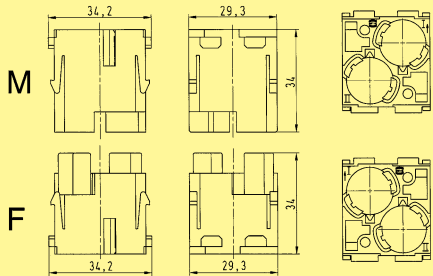

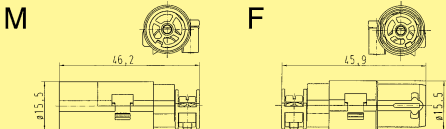


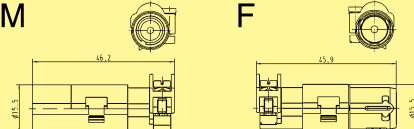
 


Number of contacts

# 2

Identification	Part number		Drawing	Dimensions in mm
	Male insert (M)	Female insert (F)		
<b>Module</b>  	<b>09 14 002 3001</b>	<b>09 14 002 3101</b>	 <p>M F</p> <p>Contact arrangement view from termination side</p>	

Han Modular

Identification	Wire gauge (mm²)	Part number		Drawing	Dimensions in mm
		Male contact	Female contact		
<b>Han® D Coax contact</b> 1 + shielding, 75 Ω Han D® crimp contacts  		<b>09 15 001 3013</b>	<b>09 15 001 3113</b>	 <p>M F</p>	
Han D® Crimp contact gold plated  	0.14-0.37 0.5 0.75 1 1.5 2.5	<b>09 15 000 6124</b> <b>09 15 000 6123</b> <b>09 15 000 6125</b> <b>09 15 000 6122</b> <b>09 15 000 6121</b> <b>09 15 000 6126</b>	<b>09 15 000 6224</b> <b>09 15 000 6223</b> <b>09 15 000 6225</b> <b>09 15 000 6222</b> <b>09 15 000 6221</b> <b>09 15 000 6226</b>		
<b>Han® E Coax contact</b> 1 + shielding, 50 Ω Han E® crimp contacts  		<b>09 15 001 3023</b>	<b>09 15 001 3123</b>	 <p>M F</p>	
Han E® contacts gold plated  	0.14-0.37 0.5 0.75 1 1.5 2.5 4 5.5	<b>09 33 000 6117</b> <b>09 33 000 6122</b> <b>09 33 000 6115</b> <b>09 33 000 6118</b> <b>09 33 000 6116</b> <b>09 33 000 6123</b> <b>09 33 000 6119</b> <b>09 33 000 6139</b>	<b>09 33 000 6217</b> <b>09 33 000 6222</b> <b>09 33 000 6215</b> <b>09 33 000 6218</b> <b>09 33 000 6216</b> <b>09 33 000 6223</b> <b>09 33 000 6221</b> <b>09 33 000 6239</b>		

Order crimp contacts separately

Stock items in bold type