



81104 TN

Dimensions

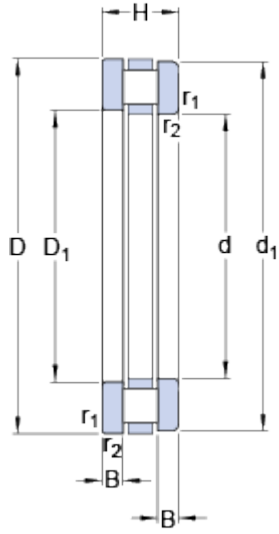

d		20	mm
D		35	mm
H		10	mm
d ₁		35	mm
D ₁		21	mm
B		2.75	mm
r _{1,2}	min.	0.3	mm

Abutment dimensions

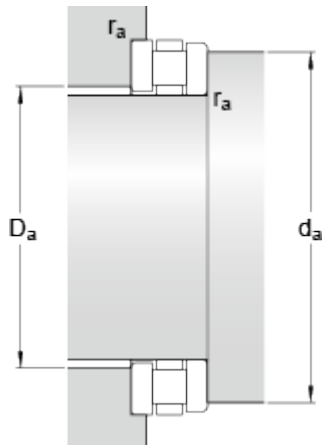

d _a	min.	34	mm
D _a	max.	21	mm
r _a	max.	0.3	mm

Calculation data

Basic dynamic load rating	C	18.6	kN
Basic static load rating	C ₀	48	kN
Fatigue load limit	P _u	4.6	kN
Reference speed		3800	r/min
Limiting speed		7500	r/min

Mass

Mass bearing		0.037	kg
--------------	--	-------	----

Appertaining products

Roller and cage thrust assembly	K 81104 TN
Shaft washer	WS 81104
Housing washer	GS 81104

