


Data Sheet

Alarm 8C SCR PVC

Cross Section:

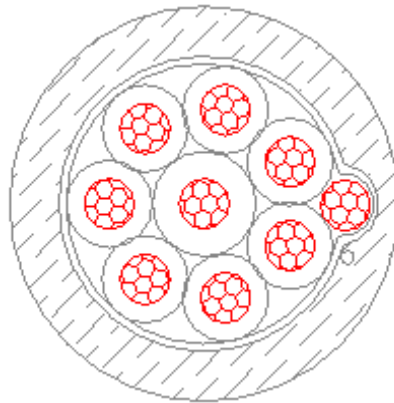

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Construction:

Conductor: Tinned Copper Claded Aluminium

Conductor Dia. (mm): TCCA0.19±0.008 x 7

Insulation: PVC

Insulation Dia. (mm): 1.00±0.08 x 7C
1.20±0.08 x 1C

Al-Pet Shield

Coverage: ≥115%

Drain wire: Tinned Copper Claded Aluminium

Drain wire Dia. (mm): TCCA0.19±0.008 x 7

Nylon rip cord: 150D

Jacket: PVC

Outer Dia. (mm): 4.60±0.2

Colour:

The color of the insulation: green, yellow, white, black, blue, red, orange and brown

The jacket color: According to customer

Marking:

According to customer

Performance:

Electrical Characteristics:

Max. Conductor DC Resistance at 20°C (Ω/Km) : <177

Min. Insulation DC Resistance at 20°C (MΩ *KM) : >200