


PS4008 DATA SHEET rev. 1


Description: 24VDC @ 1A regulated assembly

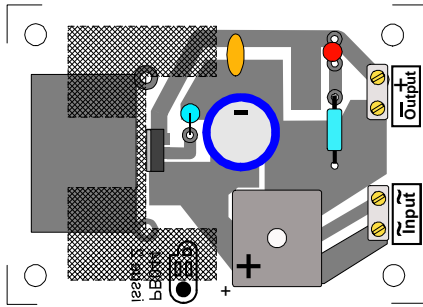

Electrical specification:
Input: 24 – 27*VAC, 50Hz
Output: 24VDC @ 1A

Max. ripple / noise: 2mVrms
Load regulation: $\pm 0.15\%$
* For loads below 600mA
this upper limit can be
increased to 30VAC

Caution: under full load the heatsink will get hot

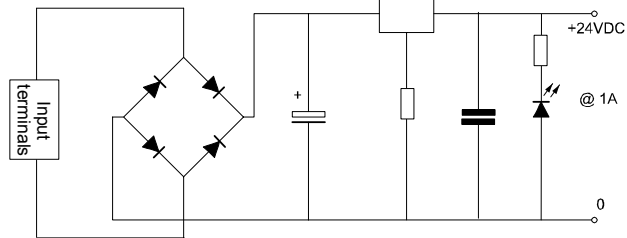

Circuit diagram