


Deep groove ball bearings, single row, SKF Energy Efficient (E2) bearings



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
45	100	25	52,7	31,5	1,34	17000	8700	0,83	E2.6309-2Z/C3

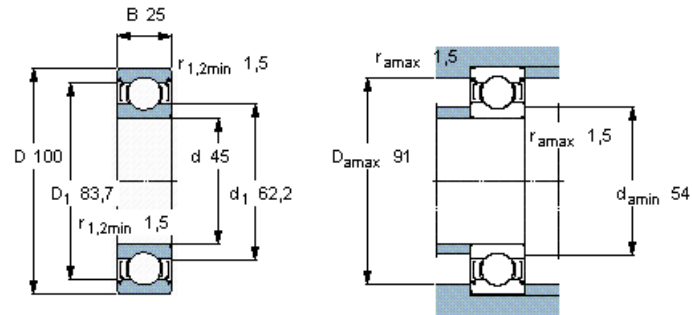

Calculation factors

k_r 0,03
 f_0 13