


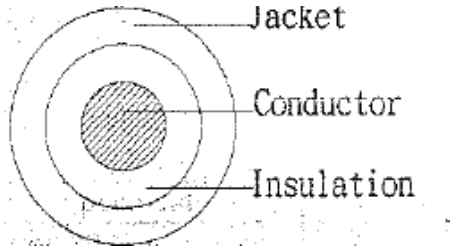

Product Name:	UL1385 24AWG
Product Discription:	UL1385 24AWG
Specification No.:	SPEC-UL1385-24AWG
Customer's Name:	

Description					Construction							
Rated Voltage:		No voltage rating			Conductor		Stranded Tinned Copper					
Rated Temperature:		125℃			Size(AWG)		24					
Reference Standard:		UL758			Construction(±0.004mm)		11/0.16					
Cross Section					Stranded Dia.(mm)Ref.		0.61					
					Insulation Material		XL-PE		Jackert Material		XL-PVDF	
					Insulation Color		White		Jacket Color		Any color	
					Ave Thickness(mm)		0.15		Ave Thickness(mm)		0.10	
					Min Thickness(mm)		0.12		Min Thickness(mm)		0.08	
					Insulation Dia.(±0.10mm)		0.90		Jacket Dia.(±0.10mm)		1.10	
Marking					Remark:							
No cable marking					8918741 Red		8918744 Blue		8918763 Grey		8918766 Violet	
					8918738 Black		8918748 White		8918750 Yellow			
					8918732 Brown		8918757 Green		8918754 Orange			
Applications					Characteristics					Customer Approve		
Internal wiring of electronic equipment.					Test Item			Standard Value			Seal & Stamp	
					Test Material			XLPE and XLPVDF(ROHS)				
					Insulation resistance(20℃ MΩ/KM			0. 75				
					Vol. Tesr(AC.V.60S) (V)			500				
					Flammability Test			Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)			94.2(MAX)			Signature: Date:	
Version	Description	Drawn by	Approved by	Date								
0	New document issue	YanBin	Jason	10/08/2015								