


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
31,75	73,025	29,37	70,4	95	6700	10000	HM 88542/2/510/2/QCL70

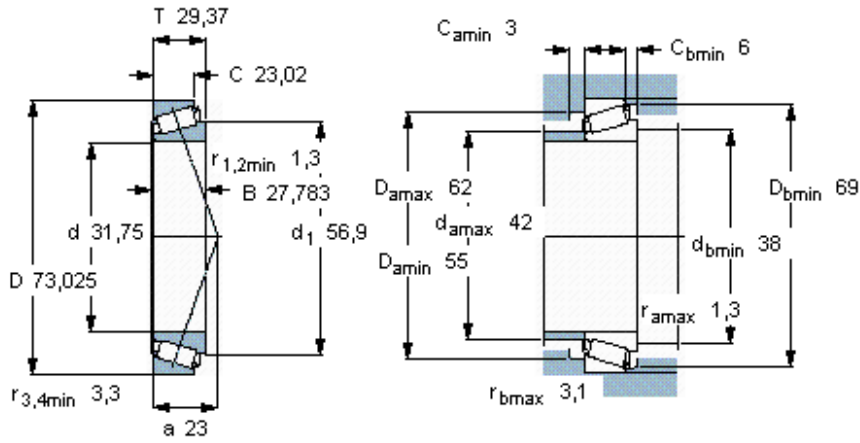

Calculation factors

e 0,54

Y 1,1

Y_0 0,6