




Professionally approved products.

Product Datasheet

Polyamide Terminal Blocks with Vertical Plug

EN

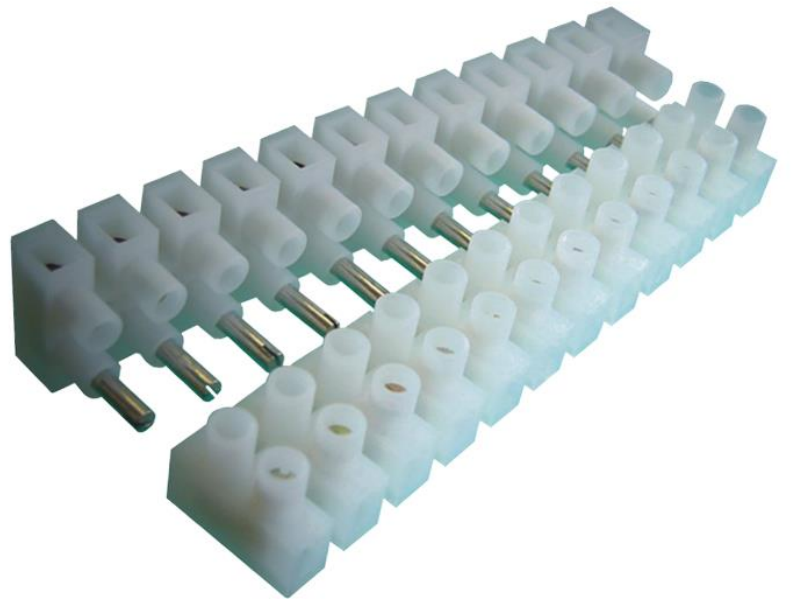

Specification

HOUSING: POLYAMIDE (PA 66)

INSERTS: NICKEL PLATED BRASS

SCREWS: GALVANISED STEEL


TEMP.: 105 °C

COLOR: NATURAL

Standard: VDE & MULTI-APPROVALS

Features:
SEMI-RIGID;
FLAME RETARDANT,;
HIGH TEMPERATURE;
ALL SCREWS ARE CAPTIVE & RAISED FOR EASY WIRING

Dimensions

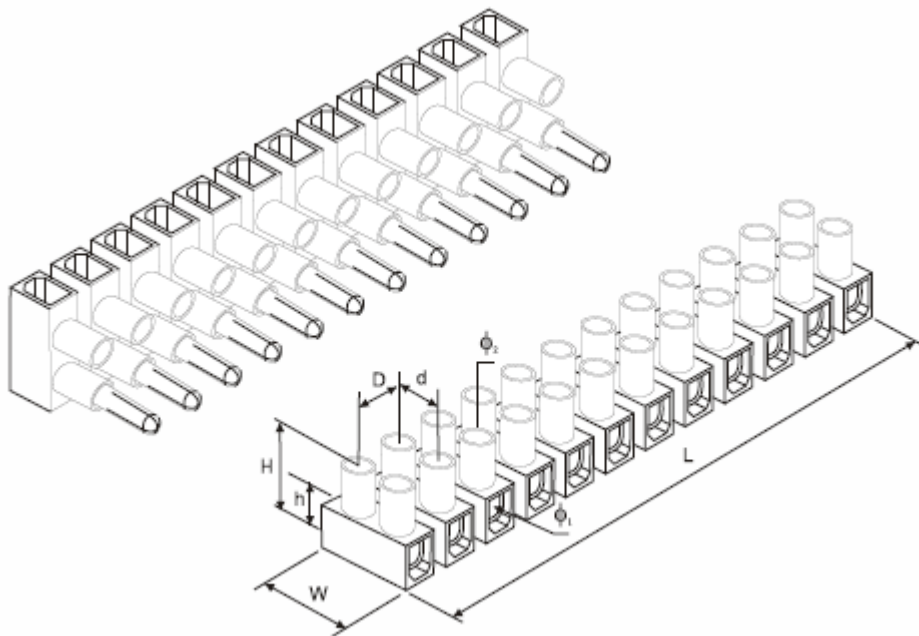



RS CODE	CROSS SECTION	CURRENT RANGE	RATED VOLTAGE	DIMENSIONS (mm)							
				W	L	Φ1	Φ2	D	d	H	h
8659837	2.5 mm ²	2.5~20A	450V	18	94	2.8	2.5	7.2	5.6	13	7
8659846	4 mm ²	3~24A	450V	20	115	3.5	3.2	10	8	15	8
8659849	6 mm ²	5~32A	450V	24	138	4.2	3.5	12	9.5	19	10

Cross Section:rated for rigid wire and cables (if for flexible wire, it should be reduced one-step, i.e. 6mm² is 4mm²)
Φ1 wire entry hole diameter **Φ2** fixing hole diameter