

Datasheet

RS Unshielded Test Lead Wire 1 mm² CSA 500 V Black PVC Single Core, 199 Strands 5m

RS Stock No. 748-1960



Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

Single

Cable Construction

Conductor	Bare Copper
Cross section	1.0mm ²
Construction(±0.003mm)	0.08× 199
Standard Dia.	1.30
Jacket	PVC
Thickness	1.25
Jacket Dia.(mm)	3.90±0.15
Color	Red(RAL3000): Black;

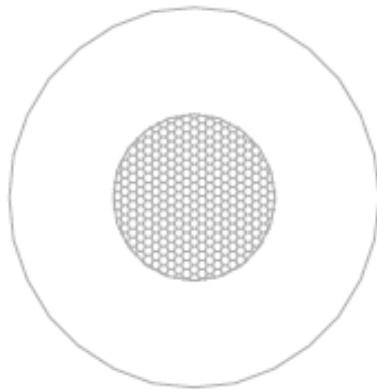
Marking

No Printing

PACKAGING

5M/ plastic Bag

Suitable pieces/Box

**Electrical Characteristics**

Max.Conductor DC Resistance at 20 °C (Ω /Km)	18.7
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	>500
Rated Temperature(°C)	-20~+80
Rated Voltage (V)	300/500