


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
38	63	17	36,9	52	7500	11000	JL 69349/310/Q

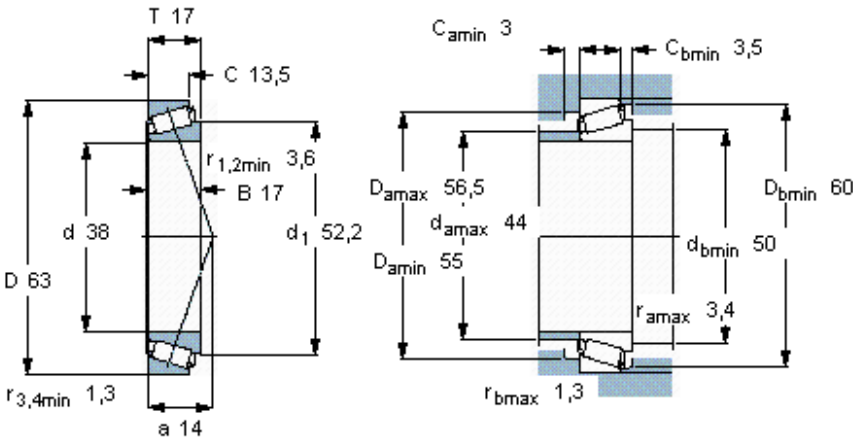

Calculation factors
e 0,43
Y 1,4
Y₀ 0,8