

## Classic ECO A55

CLAS.ECO A55 18W 240V B22 SLV

0023131

### Range features



### PRODUCT OVERVIEW

Ordering number	0023131
Light colour	828 Homelight
Technology	Halogen
Energy class	D
Average life (Rated) (h)	2000
Lamp finish	Clear
Lamp shape	GLS A55
Dimmable	Yes
Cap/Base	B22
Type	Classic 'A' Shape
EAN code	5410288231310
CRI (Ra)	100
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	180
Watt (Nominal) (W)	18
Equivalent watt (W)	21
Voltage (V)	240

# Classic ECO A55

CLAS.ECO A55 18W 240V B22 SLV

**0023131**

## DATA TABLE

### General data

<b>Technology</b>	Halogen
<b>Ordering number</b>	0023131
<b>Average life (Nominal) (h)</b>	2000
<b>Average life (Rated) (h)</b>	2000
<b>Energy saving lamp</b>	No
<b>Energy class</b>	D
<b>Lamp finish</b>	Clear
<b>Lamp shape</b>	GLS A55
<b>Dimmable</b>	Yes
<b>Cap/Base</b>	B22
<b>Type</b>	Classic 'A' Shape
<b>EAN code</b>	5410288231310
<b>E-number SE</b>	8355982
<b>Product name</b>	CLAS.ECO A55 18W 240V B22 SLV
<b>Lamp mercury content (mg)</b>	0
<b>Starting time (max) (s)</b>	0.01
<b>Warm-up time to 60% of full light (max) (s)</b>	Instant full light
<b>Control gear required</b>	No
<b>Fixture rating</b>	Open
<b>IEC Reference</b>	IEC 60357
<b>IEC Reference 2</b>	IEC 60432-2
<b>Intended purpose</b>	General lighting
<b>No. of switching cycles before premature failure (min)</b>	> 8000
<b>Special purpose lamp</b>	No
<b>Transformer required</b>	No
<b>Sales pack quantity</b>	10
<b>Optimal operating condition (°C)</b>	25

### Optical data

<b>Light colour</b>	828 Homelight
<b>CRI (Ra)</b>	100
<b>Suitable for accent lighting</b>	No
<b>Beam angle(°)</b>	na
<b>Colour temperature (K)</b>	2800
<b>Luminous flux (Rated) (lm)</b>	180
<b>Lumen maintenance at end of nominal life (%)</b>	80
<b>Luminous flux (Nominal) (lm)</b>	180

## Classic ECO A55

CLAS.ECO A55 18W 240V B22 SLV

**0023131**

### Electrical data

<b>kWh per 1000 hours burning time</b>	18
<b>Watt (Rated) (W)</b>	18
<b>Watt (Nominal) (W)</b>	18
<b>Equivalent watt (W)</b>	21
<b>Voltage (V)</b>	240
<b>Lamp power factor</b>	1

### Physical data


<b>Lamp Length (mm) - C/L</b>	98.5
<b>Lamp Diameter (mm) - D</b>	56
<b>Packaging outer width (cm)</b>	30
<b>Packaging outer length (cm)</b>	59.5
<b>Packaging outer height (cm)</b>	22
<b>Packaging single width (cm)</b>	5.5
<b>Packaging single length (cm)</b>	5.5
<b>Packaging single height (cm)</b>	9.6

## Classic ECO A55

CLAS.ECO A55 18W 240V B22 SLV

0023131

### TECHNICAL DRAWINGS

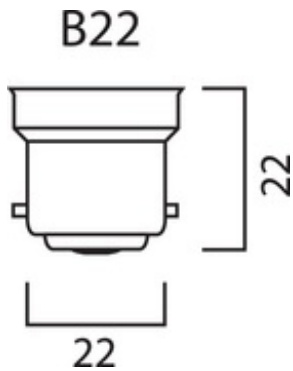

### ENERGY LABEL

