


## Data Specification Sheet

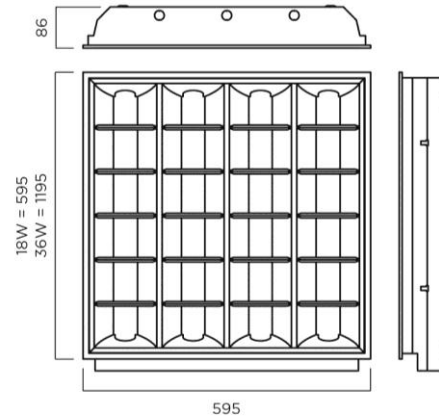

### MRB418HF Recessed High Frequency Modular 4x18W Fittings

<b>Code</b>	MRB418HF. MRB418EMHF
<b>Description</b>	Recessed 4 x 18W T8 modular fitting
<b>Overall dimensions (mm) Depth-Length-Width</b>	(D)86mm (L)595mm (W)595mm
<b>Product weight</b>	4.8kg
<b>Wattage</b>	4 x 18W T8
<b>Circuit Watts</b>	67W
<b>Recommended product location</b>	Indoor
<b>Finishes available</b>	White
<b>Control Gear Type</b>	Knightsbridge H.F. Electronic Knightsbridge H.F. Electronic Integral Emergency 3Hr maintained
<b>Dimmable</b>	No
<b>Lamp Supplied</b>	No
<b>Class</b>	Class I. Must be Earthed
<b>IP</b>	IP20
<b>Photometric Testing</b>	Yes
<b>Instruction sheet</b>	Yes
<b>Origin of manufacture</b>	China
<b>Main materials:</b>	
• <b>Chassis</b>	Pressed Steel powder coated
• <b>Louvre</b>	Mirror finish aluminium
<b>Method of fix</b>	Lay-in suitable for 600mm x 600mm recessed exposed T ceilings
<b>Lampholder cap and make</b>	G5/ BJB
<b>Electrical Connections</b>	10A L.E.N. Nylon Connector, Screw Terminals
<b>F mark</b>	Yes
<b>CE mark</b>	Yes
<b>Quality Assurance System</b>	Yes ISO 9001 QMS
<b>Batch coding details on product</b>	Yes
<b>Certificate of Conformity</b>	Yes
<b>Manufactured in accordance</b>	EN60 598

ML Accessories Ltd. reserves the right to withdraw, improve or modify any design without prior notification.

ML Accessories Ltd. cannot be held responsible for the incorrect application of any product.