


# KAE1H

operating head 45 x 45 mm - black color - black handle - blank for engraving

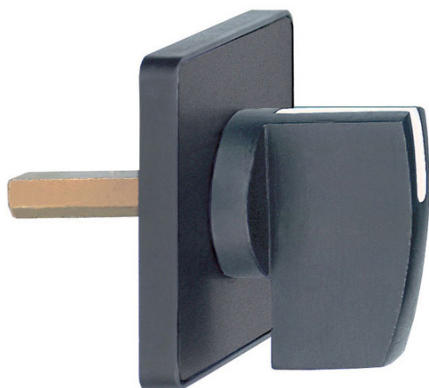

## Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KAE
Product compatibility	Rear mounting bodies 12 and 20 A by 4 holes
Cam switch head type	With front plate 45 x 45 mm
Type of operator	Black handle , length = 35 mm
Rotary handle padlocking	Without
Presentation of legend	With mat black legend

## Complementary

Mechanical durability	1000000 cycles
Length	35 mm
Product weight	0.029 kg

## Environment

Protective treatment	TC
Ambient air temperature for operation	-25...55 °C
Ambient air temperature for storage	-40...70 °C
Shock resistance	30 gn conforming to IEC 68-2-27
Vibration resistance	5 gn , 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP40 conforming to IEC 529 IP40 conforming to NF C 20-010
RoHS EUR conformity date	0910
RoHS EUR status	Compliant

The information provided in this documentation contains general descriptions and/or technical characteristics of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.