



ENGLISH

Datasheet

PVC 25m Long Blue Flexible Tube Reinforced, 55mm Bend Radius

RS Stock number 339-6067

AIR-CORD ULTRA FLEXIBLE PVC AIR HOSE - CXL series

Special Features

- Resistance to a wide range of chemicals (see Chemical Resistance Table)
- Silicone free
- Abrasion resistance - good
- Made from Cadmium free materials
- Kink resistance - good
- Ageing - outstanding resistance
- Ergonomic
- High flexibility
- Service temperature -15°C to +60°C
- Unique manufacturing process - patent no. 0036674
- Super lightweight
- Highly visible metallic blue finish
- All finished coils shrink wrapped





AIR-CORD ULTRA FLEXIBLE PVC AIR HOSE

(U.K. And European Sizes)

ENGLISH

Product Ref.	I.D. mm	O.D. mm	Weight per coil kgs	Suggested max. working pressure +23°C (3:1 safety)	
				Bar	PSI
CXL 06	6	9	1.27	14	200
CXL 08	8	10.5	1.69	14	200
CXL 10	10	13	2.08	12	175
CXL 12	12	16.5	3.25	11	160

Conforms to Product Standards:

BS 6066 : 1981 (1986)

ISO 5774 : 1980

Test Methods & Procedures:

BS EN ISO 7751 : 1997

BS EN ISO 1307 : 1996

ISO 1402 : 1994


BS EN 28033 : 1993

BS EN 24671 : 1993

ISO 8033 : 1991

Please see Standards Index for further information

CXL RANGE Pressure/Temperature Relationships

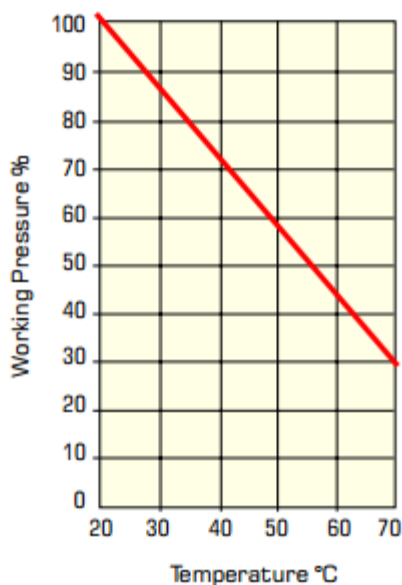

Max. recommended continuous working temperature = 60°C