



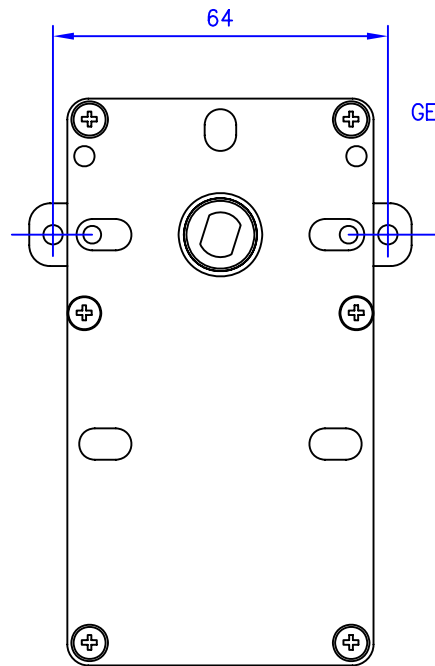

GEARBOX COVER
TAPPED M4
2 POSITIONS

S.R.B.F. SHAFT 2 WHEEL
BALL RACE BEARINGS (MOTOR)
NOISE REDUCING GREASE

APPROVED	
SIGNATURE	DATE

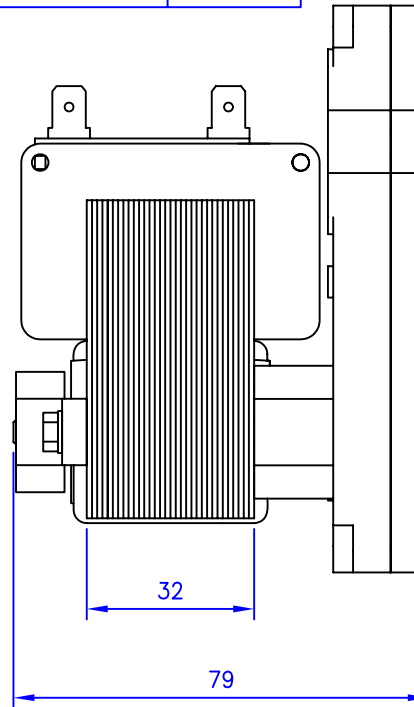


CW
FROM
FRONT

GEARBOX BASE
TAPPED M6
2 POSITIONS

LABEL DETAILS

Job No.	RS	RoHS
	DATE	✓
	8776241	
	230V 50Hz 5rpm	

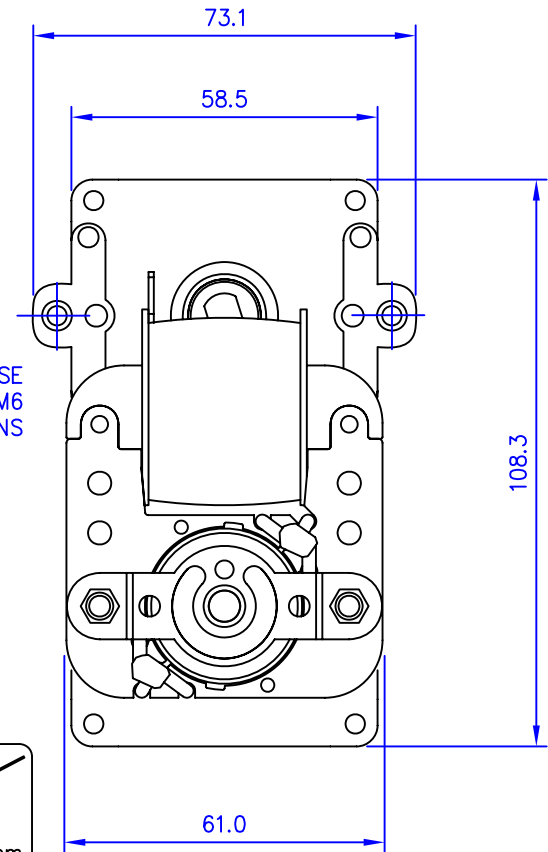

MOTOR SPEC

MEM 390 (230v 50Hz)
1.25" BOBBIN (NYLON – GLASS FILLED CLASS F)
SOLDERABLE POLYURETHANE WIRE (CLASS H, UL APPROVED)
125°C SELF RE-SETTING THERMOSTAT (UL APPROVED)
6.35mm MALE TAGS FITTED
COVER WITH GLASS CLOTH TAPE (CLASS F)

TECHNICAL DATA

INPUT POWER @ 230v 50Hz – 26WATTS
NOMINAL CURRENT @ 230v 50Hz – 0.22Amps
STALLED CURRENT @ 230v 50Hz – 0.35Amps
OUTPUT TORQUE @ 230v 50Hz – 16Nm
TEMP. RISE – 21°C–90°C/3Hrs

CONTINUOUSLY RATED

MELLOR ELECTRICS Ltd

BLACKBURN ENGLAND

APPROVED

DRAWN

LC

20/03/15

CUSTOMER

MELLOR ELECTRICS

DESCRIPTION

T14 5RPM 230v 50Hz

PART No

KB1003