

Schroff®
MAIN CATALOG

EQUIPMENT PROTECTION SOLUTIONS

24TH EDITION | OCTOBER 2012

07.1 Front panels

Overview	0
Cabinets	1
Wall mounted cases	2
Accessories for cabinets and wall mounted cases .	3
Climate control .	4
Electronics cases	5
Sub racks/ 19" chassis	6
Front panels, plug-in units ...	7
Systems	8
Power supply units	9
Backplanes ...	10
Connectors, front panel component system	11
Appendix	12

Front panels



04292001

Standards

- IEC 60297-3-101/IEEE 1101.1/10




ServicePLUS

- e.g. individual colouring
- e.g. customised cut-outs
- e.g. printing
- e.g. mounting service
- e.g. special dimensions


www.frontpanelexpress.eu

30407004

**FRONT PANEL
EXPRESS**

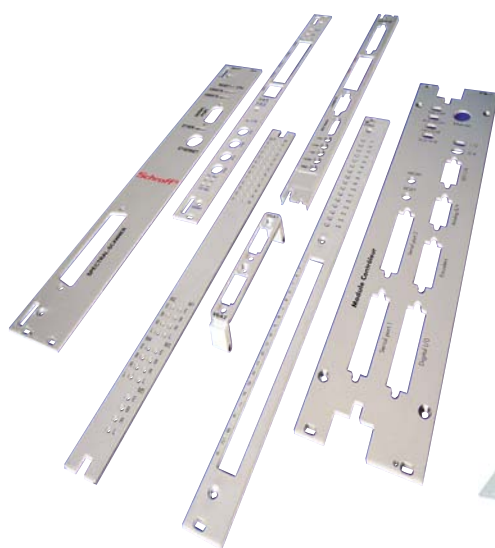

32304003

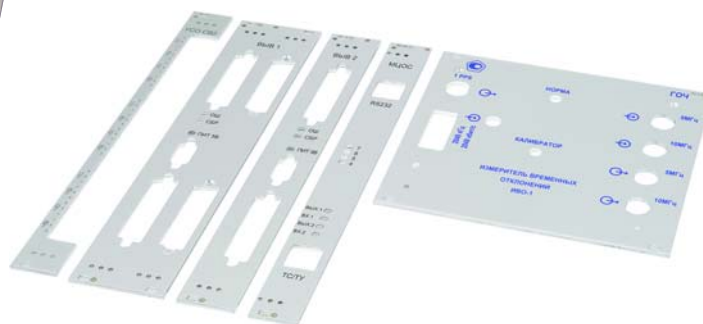

04210001 04603009



Downloads and additional important information can be found on the Internet under www.schroff.biz

Front panels for fitting in subracks, cases and systems

- Extensive standard range with various finishes and materials (aluminium or stainless steel)
- Front Panel Express:
Fast delivery service of customised versions (from 2 days)
- EMC shielding retrofittable



04292001

Front panels, unshielded

- Aluminium, clear anodised
- Aluminium, clear pre-anodised, cut edge untreated
- Aluminium, front anodised, rear iridescent green chromated
- Other finishes on request



04600006

Front panels shieldable, flat

- With lateral grooves to fit EMC gaskets (stainless steel)
- Compatible with the shielded U profile version



04602004

Front panels, shieldable, U profile

- With lateral groove to fix a textile self-adhesive EMC gasket
- Compatible with the shielded flat version
- High robustness through U profile



04295001 04295002

Further front panels

- Hinged/folding front panels
- Front panels with GND/earthing
- Mezzanine front panels
- AdvancedTCA front panels
- MicroTCA front panels
- AdvancedMC front panels

Front panels

- Unshielded 7.4
- Shieldable 7.5
- EMC stainless steel gaskets ... 7.6
- Assembly tool .. 7.6

Front panels

- Shieldable (U profile) 7.7
- EMC textile gasket 7.6

Further front panels


- Hinged 7.8
- Hinged, shielded 7.9
- For D-Sub connectors 7.10
- For Coax connectors 7.11
- 3 U with GND/earthing 7.11
- Mezzanine front panels 7.12

Assembly kit ... 7.107

- AdvancedTCA front panels 8.12
- MicroTCA front panels 8.65
- AdvancedMC front panels 8.60

Front panels

Front panels, unshielded

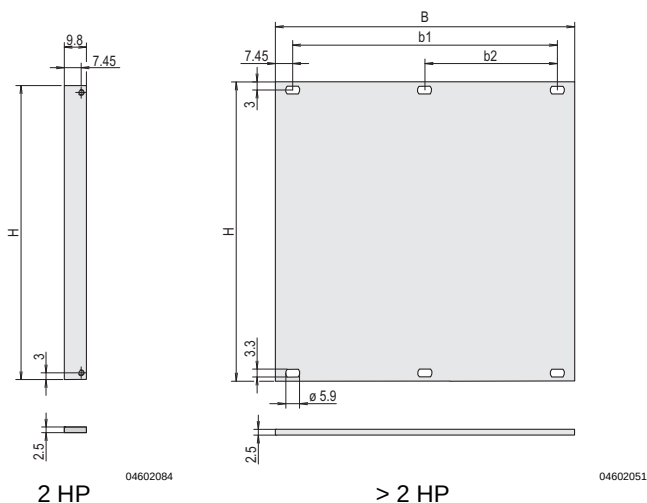

■ Front panel, Al, 2.5 mm

■ Versions:

- Al, anodised
- Al, anodised, cut edges plain
- Al, front anodised, rear iridescent green chromated

Note

- Other sizes and finishes available on request
- Please order fixing material separately, see chapter Assembly parts, page 7.107

Order Information

Height H	Width	B	b1	b2	Qty	Anodised, cut edges plain	Anodised	Front anodised, rear colorless chromated
U	mm	HP	mm	mm	1)	Part no.	Part no.	Part no.
1	39.5	84	426.4	411.5	203.2	1	–	20850-426
2	84.0	84	426.4	411.5	203.2	1	30818-271	30807-416
3	128.4	2	9.8	–	–	1 (SPQ 5) ¹⁾	30810-433	30810-432
3	128.4	3	14.9	–	–	1 (SPQ 5) ¹⁾	30818-272	30807-508
3	128.4	4	20.0	–	–	1 (SPQ 5) ¹⁾	30818-273	30807-481
3	128.4	5	25.0	–	–	1 (SPQ 5) ¹⁾	30818-274	30807-510
3	128.4	6	30.1	–	–	1 (SPQ 5) ¹⁾	30818-275	30807-482
3	128.4	7	35.2	–	–	1 (SPQ 5) ¹⁾	30818-276	30807-509
3	128.4	8	40.3	25.4 ²⁾	–	1 (SPQ 5) ¹⁾	30818-277	30807-484
3	128.4	10	50.5	35.6	–	1 (SPQ 5) ¹⁾	30818-279	30807-483
3	128.4	12	60.6	45.7	–	1 (SPQ 5) ¹⁾	30818-281	30807-485
3	128.4	14	70.8	55.9	–	1 (SPQ 5) ¹⁾	30818-282	30807-501
3	128.4	21	106.3	91.4	–	1 (SPQ 5) ¹⁾	30818-289	30807-487
3	128.4	28	141.9	127.0	–	1 (SPQ 5) ¹⁾	30818-296	30807-496
3	128.4	42	213.0	198.1	101.6 ²⁾	1	30818-310	30807-494
3	128.4	63	319.7	304.8	157.5	1	30818-331	30808-067
3	128.4	84	426.4	411.5	203.2	1	30818-352	30807-506
4	172.9	84	426.4	411.5	203.2	1	30818-434	30807-596
6	261.8	2	9.8	–	–	1 (SPQ 5) ¹⁾	30818-747	30818-741
6	261.8	4	20.0	–	–	1 (SPQ 5) ¹⁾	30818-518	30807-778
6	261.8	5	25.0	–	–	1 (SPQ 5) ¹⁾	30818-519	30807-777
6	261.8	6	30.1	–	–	1 (SPQ 5) ¹⁾	30818-520	30807-752
6	261.8	7	35.2	–	–	1 (SPQ 5) ¹⁾	30818-521	–
6	261.8	8	40.3	25.4 ²⁾	–	1 (SPQ 5) ¹⁾	30818-522	30807-779
6	261.8	10	50.5	35.6	–	1 (SPQ 5) ¹⁾	30818-524	30807-753
6	261.8	12	60.6	45.7	–	1 (SPQ 5) ¹⁾	30818-526	30807-755
6	261.8	14	70.8	55.9	–	1 (SPQ 5) ¹⁾	30818-528	30807-758
6	261.8	16	80.9	66.0	–	1 (SPQ 5) ¹⁾	30818-530	30807-780
6	261.8	21	106.3	91.4	–	1 (SPQ 5) ¹⁾	30818-535	30807-757
6	261.8	28	141.9	127.0	–	1 (SPQ 5) ¹⁾	30818-542	30807-766
6	261.8	42	213.0	198.1	101.6 ²⁾	1	30818-556	30807-764
6	261.8	63	319.7	304.8	157.5	1	30818-577	30807-771
6	261.8	84	426.4	411.5	203.2	1	30818-598	30807-776
9	395.1	84	426.4	411.5	203.2	1	–	–


1) SPQ (standard pack quantity): Part number includes 1 piece, but delivery is exclusively made in standard pack quantity (SPQ); please order at least the SPQ quantity or a multiple

2) This dimension is only available for "front anodised, rear iridescent green chromated" version

■ Please order fixing material (sleeves, collar screws) separately, see page 7.107


Front panels

Front panels, shieldable

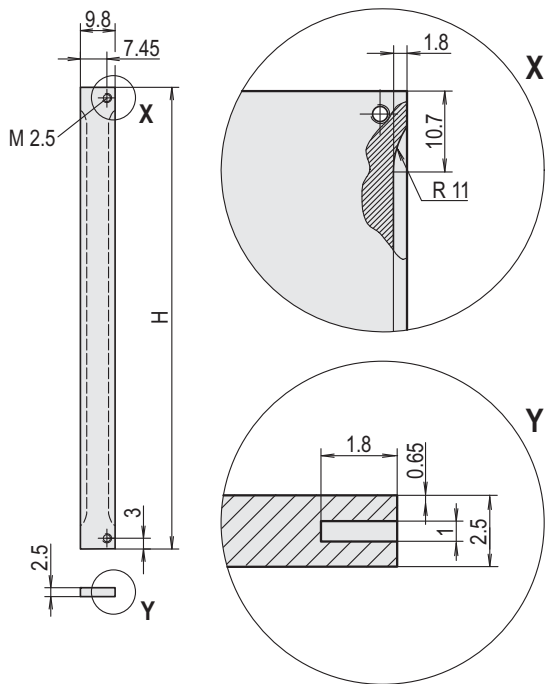

2 HP

04602052

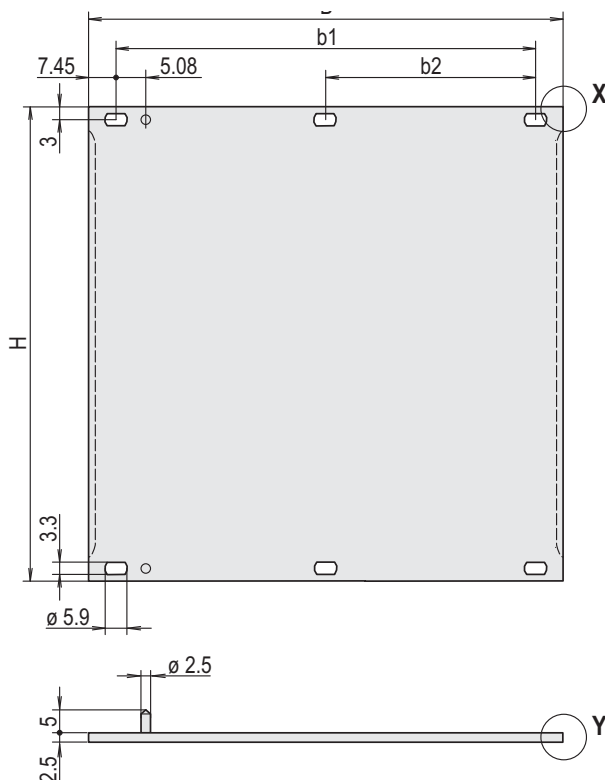

> 2 HP

04608154

- Front panel, Al, 2.5 mm, front anodised, rear iridescent green chromated, 2 alignment pins pressed-in, stainless steel
- Shielding with stainless steel EMC gasket

Order Information

Height H U	mm	Width B HP	mm	b1 mm	b2 mm	Align- ment pin	Qty	Part no.
2	84	84	426.4	411.5	203.2	–	1	30846-588
3	128.4	2	9.8	–	–	–	1 (SPQ 5) ¹⁾	30846-864
3	128.4	3	14.9	–	–	x	1 (SPQ 5) ¹⁾	20846-425
3	128.4	4	20	–	–	x	1 (SPQ 5) ¹⁾	20846-426
3	128.4	5	25	–	–	x	1 (SPQ 5) ¹⁾	20846-427
3	128.4	6	30.1	–	–	x	1 (SPQ 5) ¹⁾	20846-428
3	128.4	7	35.2	–	–	x	1 (SPQ 5) ¹⁾	20846-429
3	128.4	8	40.3	25.4	–	x	1 (SPQ 5) ¹⁾	20846-430
3	128.4	10	50.5	35.6	–	x	1 (SPQ 5) ¹⁾	20846-431
3	128.4	12	60.6	45.7	–	x	1 (SPQ 5) ¹⁾	20846-432
3	128.4	14	70.8	55.9	–	x	1 (SPQ 5) ¹⁾	20846-433
3	128.4	21	106.3	91.4	–	x	1 (SPQ 5) ¹⁾	20846-434
3	128.4	28	141.9	127	–	x	1 (SPQ 5) ¹⁾	20846-436
3	128.4	42	213	198.1	101.6	x	1	20846-437
3	128.4	63	319.7	304.8	157.5	x	1	20846-438
3	128.4	84	426.4	411.5	203.2	–	1	30846-676
4	172.9	84	426.4	411.5	203.2	–	1	30846-683
6	261.8	2	9.8	–	–	–	1 (SPQ 5) ¹⁾	30846-865
6	261.8	4	20	–	–	x	1 (SPQ 5) ¹⁾	20846-443
6	261.8	5	25	–	–	x	1 (SPQ 5) ¹⁾	20846-444
6	261.8	6	30.1	–	–	x	1 (SPQ 5) ¹⁾	20846-445
6	261.8	7	35.2	–	–	x	1 (SPQ 5) ¹⁾	20846-446
6	261.8	8	40.3	25.4	–	x	1 (SPQ 5) ¹⁾	20846-447
6	261.8	10	50.5	35.6	–	x	1 (SPQ 5) ¹⁾	20846-448
6	261.8	12	60.6	45.7	–	x	1 (SPQ 5) ¹⁾	20846-449
6	261.8	14	70.8	55.9	–	x	1 (SPQ 5) ¹⁾	20846-450
6	261.8	16	80.9	66	–	x	1 (SPQ 5) ¹⁾	20846-456
6	261.8	21	106.3	91.4	–	x	1 (SPQ 5) ¹⁾	20846-451
6	261.8	28	141.9	127	–	x	1 (SPQ 5) ¹⁾	20846-452
6	261.8	42	213	198.1	101.6	x	1	20846-453
6	261.8	63	319.7	304.8	157.5	x	1	20846-454
6	261.8	84	426.4	411.5	203.2	–	1	30846-771
9	395.1	84	426.4	411.5	203.2	–	1	30846-859

Delivery is exclusively made in Standard Pack Quantity (SPQ):

Please order at least 5 pieces or a multiple.

Pricing is per individual item.

Note


- Please order fixing material (sleeves, collar screws) separately, see page 7.107
- Please order stainless steel EMC gasket separately, see page 7.6




For further information www.schroff.biz/oneclick
oneClick search code = Part no.

Front panels

Stainless steel EMC gasket

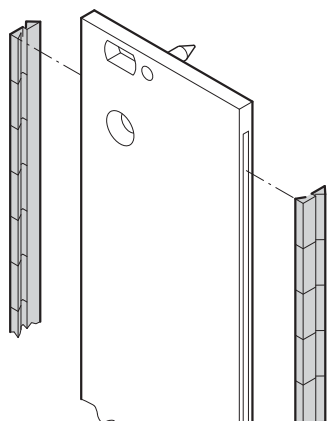

Montagewerkzeug

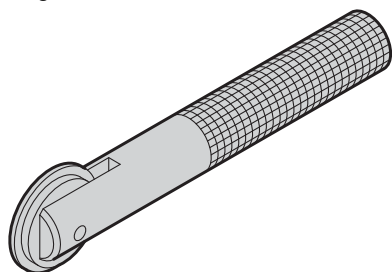

bga45760

aza45937

- The stainless steel EMC gaskets are inserted into the lateral slots of the shieldable front panels (2 pieces per front panel)

Delivery comprises

Item	Qty	Description
1	10/100	EMC gasket (stainless steel)


Order Information

Height U	Height mm	Qty/PU	Part no.
2	52	10	21101-775
3	97	10	21101-705
3	97	100	21101-706
4	142	10	21101-713
4	142	100	21101-714
5	187	10	21101-777
5	187	100	21101-778
6	232	10	21101-707
6	232	100	21101-708
9	367	10	21101-709
9	367	100	21101-710
Assembly tool for EMC gasket (stainless steel), 1 piece			24560-270

Note

- Please order assembly tool separately

Textile EMC gasket

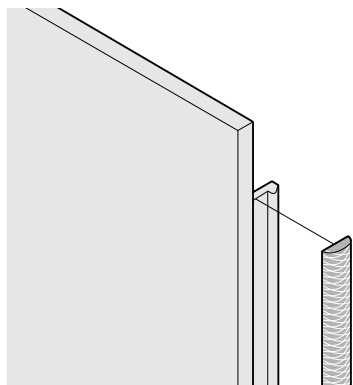

- Textile EMC gasket is glued laterally on the front panel, in the groove of the right-hand profile

- 2 temperature ranges
 - Temperature range -40... +70 °C
 - Temperature range -40... +85 °C

Delivery includes


Item	Qty	Description
1	see Order Information	EMC textile gasket, core: TPE foam (-40... +70 °C), Core: silicon with hollow chamber (-40... +85 °C), sleeve: textile cladding with CuNi coating

Order Information

Height U	Height mm	Qty/PU piece	Part no. Temperature range -40... +70 °C	Part no. Temperature range -40... +85 °C
2	52	10	21101-857	21102-857
3	97	10	21101-853	21102-853
3	97	100	21101-854	21102-854
4	142	10	21101-858	21102-858
5	187	10	21101-978	21102-978
6	232	10	21101-855	21102-855
6	232	100	21101-856	21102-856
9	365	10	21101-859	21102-859
9	365	100	21101-904	–

EMC characteristic (typical, green)

B1 (red): -40 ... -70 °C, B2 (blue): -40 ... -85 °C

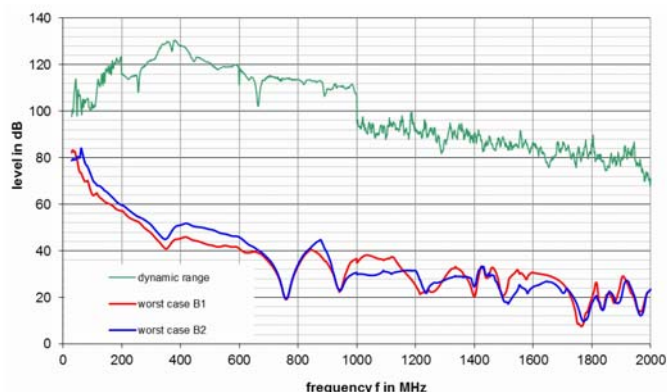

04602054


04614052

Front panels


Front panels, U profile, shieldable

2 HP

3 U

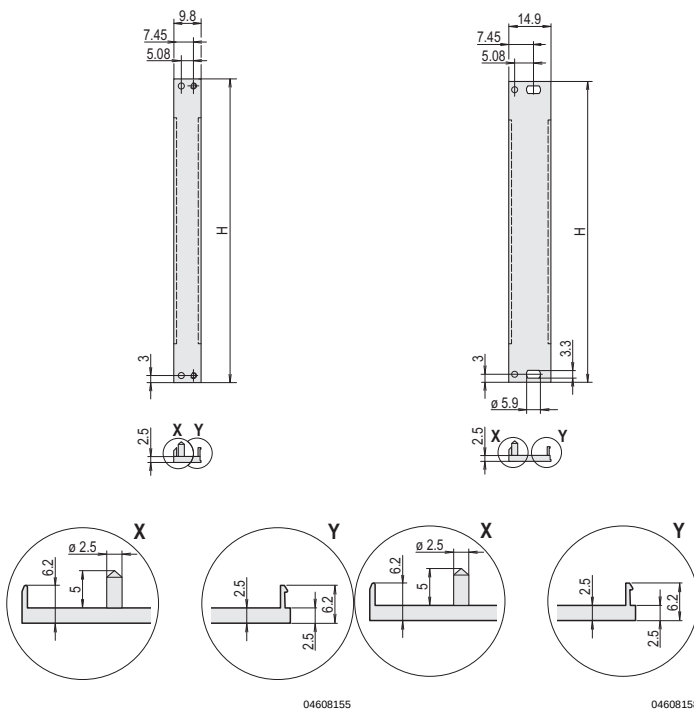

> 3 HP

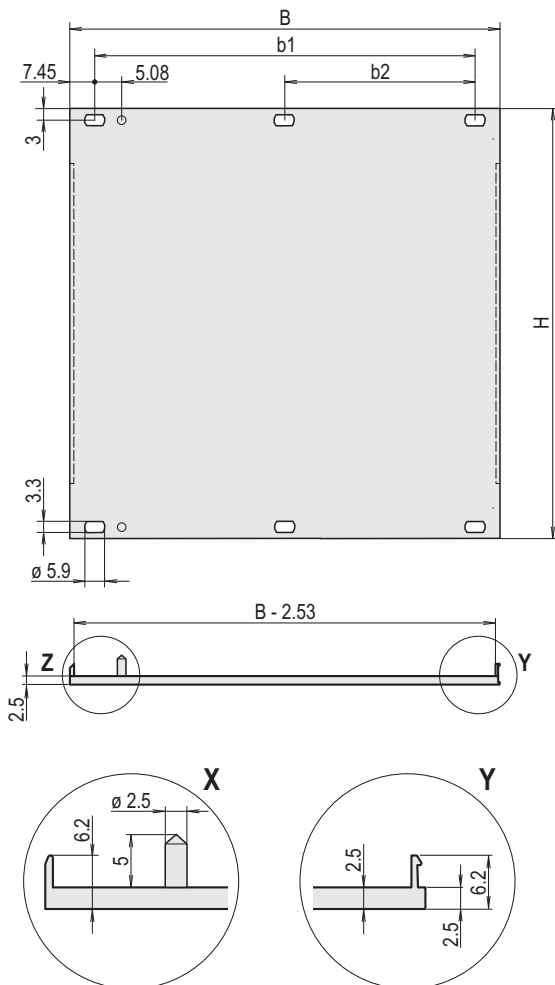

- High stability through U profile
- Front panel, U profile, Al, front anodised, rear conductive, 2 alignment pins pressed-in, stainless steel
- Differences in the finish between 2 ... 12 HP and 14 ... 84 HP

Order Information

Height H	Width B	b1	b2	Align-	Qty	Part no.		
U mm	HP mm	mm	mm	ment pin				
2	84	84	426.4	411.5	203.2	—	1 (SPQ 5)1	20848-262
3	128.4	2	9.8	—	—	x	1 (SPQ 5)1	30849-001
3	128.4	3	14.9	—	—	x	1 (SPQ 5)1	30849-004
3	128.4	4	20	—	—	x	1 (SPQ 5)1	30848-354
3	128.4	5	25	—	—	x	1 (SPQ 5)1	30848-378
3	128.4	6	30.1	—	—	x	1 (SPQ 5)1	30848-380
3	128.4	7	35.2	—	—	x	1 (SPQ 5)1	30848-382
3	128.4	8	40.3	25.4	—	x	1 (SPQ 5)1	30848-356
3	128.4	10	50.5	35.6	—	x	1 (SPQ 5)1	30848-386
3	128.4	12	60.6	45.7	—	x	1 (SPQ 5)1	30848-358
3	128.4	14	70.8	55.9	—	x	1 (SPQ 5)1	20848-013
3	128.4	16	80.9	66	—	x	1 (SPQ 5)1	20848-015
3	128.4	21	106.3	91.4	—	x	1 (SPQ 5)1	20848-020
3	128.4	28	141.9	127	—	x	1 (SPQ 5)1	20848-027
3	128.4	42	213	198.1	101.6	x	1	20848-047
3	128.4	63	319.7	304.8	157.5	x	1	20848-068
3	128.4	84	426.4	411.5	203.2	—	1	20848-097
4	172.9	84	426.4	411.5	203.2	—	1	20848-271
6	261.8	2	9.8	—	—	x	1 (SPQ 5)1	30849-002
6	261.8	4	20	—	—	x	1 (SPQ 5)1	30848-355
6	261.8	5	25	—	—	x	1 (SPQ 5)1	30848-379
6	261.8	6	30.1	—	—	x	1 (SPQ 5)1	30848-381
6	261.8	7	35.2	—	—	x	1 (SPQ 5)1	30848-383
6	261.8	8	40.3	25.4	—	x	1 (SPQ 5)1	30848-357
6	261.8	10	50.5	35.6	—	x	1 (SPQ 5)1	30848-387
6	261.8	12	60.6	45.7	—	x	1 (SPQ 5)1	30848-359
6	261.8	14	70.8	55.9	—	x	1 (SPQ 5)1	20848-106
6	261.8	16	80.9	66	—	x	1 (SPQ 5)1	20848-108
6	261.8	21	106.3	91.4	—	x	1 (SPQ 5)1	20848-113
6	261.8	28	141.9	127	—	x	1 (SPQ 5)1	20848-120
6	261.8	42	213	198.1	101.6	x	1	20848-139
6	261.8	63	319.7	304.8	157.5	x	1	20848-160
6	261.8	84	426.4	411.5	208.3	—	1	20848-189
9	395.1	84	426.4	411.5	203.2	—	1	20848-280

1) Delivery is exclusively made in Standard Pack Quantity (SPQ):
Please order at least 5 pieces or a multiple.
Pricing is per individual item.

Note

- Differences in finish between 2 ... 12 HP and 14 ... 84 HP
 - 2 ... 12 HP: one-part U-profile
 - 14 ... 84 HP: multi-part U-profile (front panel with crimped profiles)
- Please order fixing material (sleeves, collar screws) separately, see page 7.107
- Please order textile EMC gasket separately, see page 7.6

Front panels

Front panels, bottom-hinged



04295001


- Suitable for subracks (europacPRO) and cases (ratiopacPRO, propacPRO, compacPRO)
- Front panel can be unhinged at 135° (not ratiopacPRO) opening angle
- The useable width is not restricted
- Mounts on the horizontal rails
- 2 versions:
 - unshielded
 - shielded, U front panel with textile EMC gasket

Delivery comprises (kit)

Item	Qty		Description
	Unshielded	Shielded	
1	1	-	Front panel, hinged, Al, 2.5 mm, anodised, cut edges plain
1a	-	1	Front panel, U profile, hinged, Al, 2.5 mm, front anodised, rear iridescent green chromated
2	2	3	Hinge, Zn die-cast, nickel-plated
3	2	3	Sleeve, PA
4	2	3	Knurled screw M2.5 x 12.3, nickel-plated
5	-	1	EMC textile gasket, core: foam, sleeve: textile cladding with CuNi coating
6	1	1	Assembly kit

Unshielded

04602080

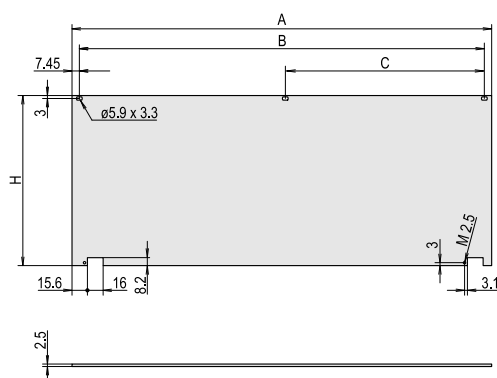


Note

- Unshielded: Dimension C for 84 HP only

Shielded

04602079

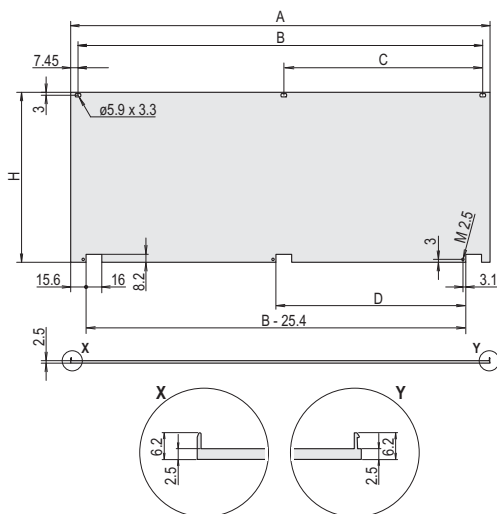

Order Information

Dimensions							Shielded	Unshielded
Height	Width	A	B	C	D	H	Part no.	Part no.
U	HP	mm	mm	mm	mm	mm		
3	28	141.9	127.0	—	—	128.4	20848-608	20838-280
3	42	213.0	198.1	101.6	86.4	128.4	20848-599	20838-271
3	63	319.7	304.8	157.5	137.2	128.4	20848-600	20838-272
3	84	426.4	411.5	208.3 ¹⁾	193.0	128.4	20848-601	20838-273
4	42	213.0	198.1	101.6	86.4	172.9	20848-605	20838-277
4	63	319.7	304.8	157.5	137.2	172.9	20848-606	20838-278
4	84	426.4	411.5	208.3 ¹⁾	193.0	172.9	20848-607	20838-279
6	28	141.9	127.0	—	—	261.8	20848-696	—
6	42	213.0	198.1	101.6	86.4	261.8	20848-602	20838-274
6	63	319.7	304.8	157.5	137.2	261.8	20848-603	20838-275
6	84	426.4	411.5	208.3 ¹⁾	193.0	261.8	20848-604	20838-276

1) Dimension with unshielded front panel

Front panels

Front panel, hinged, shielded



04295002

- Suitable for subracks (europacPRO) and cases (ratiopacPRO, propacPRO, compacPRO)
- Mounts on horizontal rails
- Front panel with textile EMC gasket
- Hinges can be fitted on left or right

Delivery comprises (kit)


Item	Qty	Description
1	1	Front panel, hinged, Al, 2.5 mm, front anodised, rear iridescent green chromated
2	2	Hinge, Zn die-cast, chrome-plated
3	1	Textile EMC gasket, core: foam, sleeve: textile cladding with CuNi coating
4	1	Assembly kit

Order Information


Height U	H mm	h mm	W mm	w mm	Part no.
3	128.4	89.9	426.4	203.2	20848-611
6	261.8	223.2	426.4	203.2	20848-617



For further information www.schroff.biz/oneclick
oneClick search code = Part no.

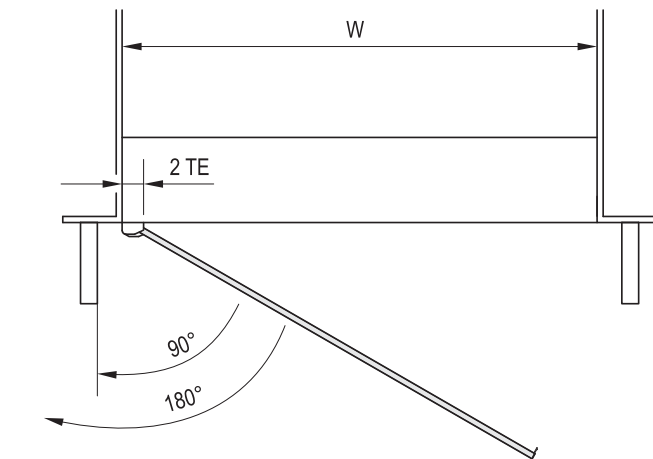

06106053

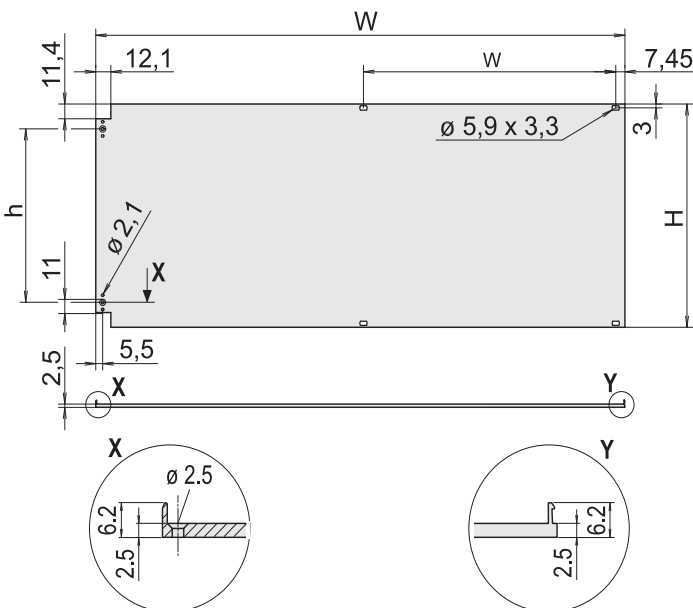

04602081

Front panels

Front panels for D-Sub connectors



Cut-out 9-pin



Cut-out 15-pin



Cut-out 25-pin



For textile EMC gasket

- 3 U/4 HP
- Aluminium, front anodised, rear iridescent green chromated
- Shielding through: stainless steel EMC or textile EMC gasket (please order separately)

Delivery comprises

Item	Description
1a	Front panel, Al, 2.5 mm, front anodised, rear iridescent green chromated
1b	Front panel, Al, 2.5 mm, front anodised, rear iridescent green chromated; for EMC stainless steel gasket
1c	Front panel, U profile, Al, 2.5 mm, front anodised, rear conductive; for EMC gasket (textile)

Order Information

Cut-out	Qty	Unshielded	For EMC gasket	
			Stainless steel	Textile
			Part no. 1a	Part no. 1b Part no. 1c
1 × 9-polig	1 piece (SPQ 5)	30118-341	30118-348	30849-749
2 × 9-polig	1 piece (SPQ 5)	30118-344	30118-351	30849-750
3 × 9-polig	1 piece (SPQ 5)	30118-347	30118-354	30849-751
1 × 15-polig	1 piece (SPQ 5)	30118-342	30118-349	30849-752
2 × 15-polig	1 piece (SPQ 5)	30118-345	30118-352	30849-753
1 × 25-polig	1 piece (SPQ 5)	30118-343	30118-350	30849-754
2 × 25-polig	1 piece (SPQ 5)	30118-346	30118-353	30849-755

Delivery is exclusively made in Standard Pack Quantity (SPQ):
Please order at least 5 pieces or a multiple.
Pricing is per individual item.

Note


- Please order fixing material (sleeves, collar screws) separately, see page 7.107
- Please order stainless steel EMC gasket separately, see page 7.6
- Please order textile EMC gasket separately, see page 7.6



For further information www.schroff.biz/oneclick
oneClick search code = Part no.

Front panels

Front panels for Coax connectors

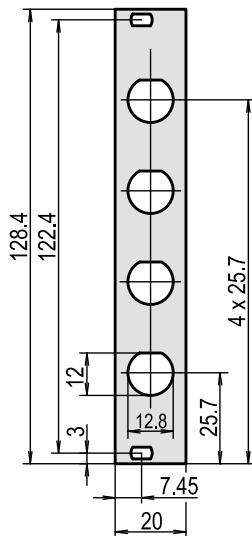

04602057

- 3 U/4 HP
- Aluminium, 2.5 mm, front anodised, rear iridescent green chromated

Order Information

Description	Qty/PU	Part no.
Cut-out 4 x Coax, unshielded	1	30118-355

Note

- Please order fixing material (sleeves, collar screws) separately, see page 7.107



For further information www.schroff.biz/oneclick
oneClick search code = Part no.

Front panels 3 U with GND/earthing connection



02998001

- Earthed front panel (protection class 1)

Delivery comprises (items 1 – 3 assembled)

Item	Qty	Description
1	1	Front panel 3 U, Al, 2.5 mm, front anodised, rear iridescent green chromated with GND/earthing connection
2	4	Plastic sleeve, PA, grey
3	4	Collar screws, M2.5 x 11 and 12.3 Pozidrive, St, nickel-plated
4	1	GND/earthing kit, length of GND/earthing cable 320 mm

Order Information

Height	Width	Qty	Part no.
U	HP		
3	7	1 piece (SPQ 5)	20119-159
3	14	1 piece (SPQ 5)	20119-160
3	21	1 piece (SPQ 5)	20119-161
3	28	1 piece (SPQ 5)	20119-162
3	42	1	20119-163

Delivery is exclusively made in Standard Pack Quantity (SPQ):
Please order at least 5 pieces or a multiple.
Pricing is per individual item.

Note


- Please order fixing material (sleeves, collar screws) separately, see page 7.107



For further information www.schroff.biz/oneclick
oneClick search code = Part no.

Front panels


PMC Mezzanine front panels

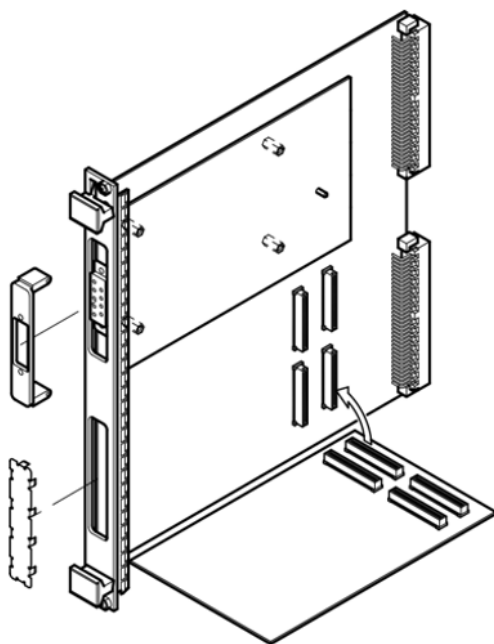

04615054

- Based on PCI 2.2 specification
(PCI = **P**eripheral **C**omponent **I**nterface)
- In accordance with PMC mezzanine specification IEEE P 1386

PMC mezzanine front panel kit, shielded, with trapezoidal extractor handle Type 1

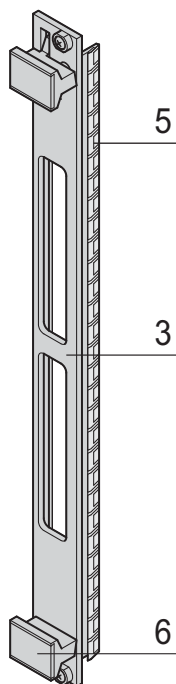

MPA44845

Item 3: front panel, item 5: EMC gasket, item 6: front handle

- PMC= **P**CI **M**ezzanine **C**ard
- For module size 194 x 74 mm2
- In accordance with specification IEEE P1386
(CMC= **C**ommon **M**ezzanine **C**ard)
- 6 U/4 HP front panel with stainless steel EMC gasket and front handles

Delivery includes (assembled)

Item	Qty	Description
3	1	PMC front panel, Al extrusion, 6 U, 4 HP, clear passivated
5	1	EMC gasket (St, stainless)
6	2	Trapeziform extraxtor handle, type 1

Order Information

Item	Description	Part No.
3+5+6	Front panel with 2 cut-outs	20897-950

Accessories


Spacer to mount PMC and FMC mezzanine boards	see page 7.15
Voltage keying/coding pin for PMC mezzanine boards	see page 7.15
PMC cover for front panel cutouts for EMC shielding, PMC gasket for mezzanine front panels	see page 7.13
PMC gasket for mezzanine front panels	see page 7.13



For further information www.schroff.biz/oneclick
oneClick search code = Part no.

Front panels

PMC cutout cover for EMC protection

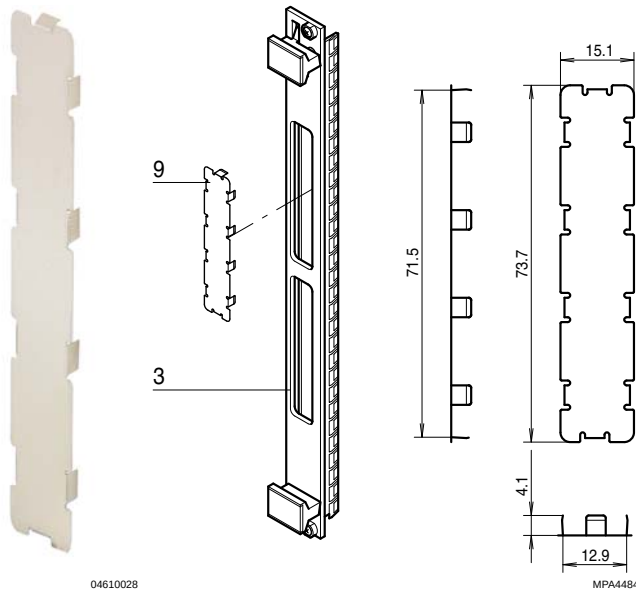

Item 9: EMC cover; Item 3: front panel

- EMC cover to close unused cut-outs in the PMC mezzanine front panels
- Material stainless steel, 0.2 mm
- Colour: black or bright

Order Information


Colour	Qty	Part no.
Black	1 piece (SPQ 10)	60835-024
Bright	1 piece (SPQ 10)	60835-022

Delivery is exclusively made in Standard Pack Quantity (SPQ):
Please order at least 10 pieces or a multiple.
Pricing is per individual item.



For further information www.schroff.biz/oneclick
oneClick search code = Part no.

PMC bezel for mezzanine front panels

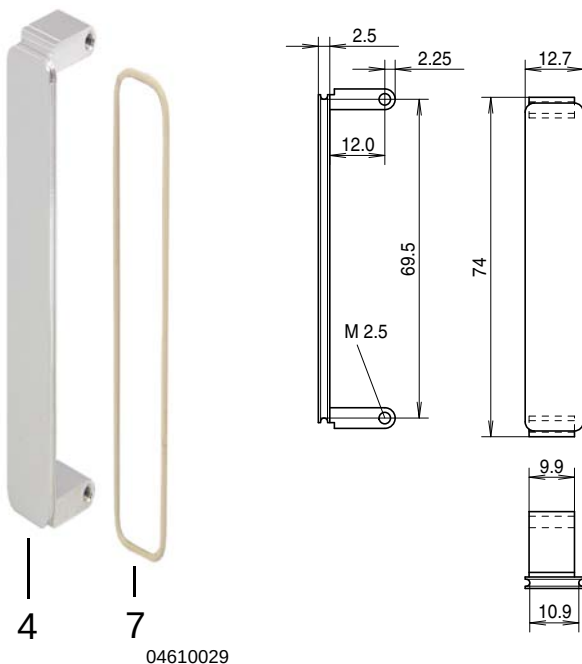

04610029

- Mezzanine front panel is fitted into PMC front panel cut-outs; EMC shielding with conductive O-ring
- Material:
 - Aluminium extrusion (anodised, contact surfaces conductive)
 - Zinc die-cast (untreated, black or chrome-plated, matt)

Delivery comprises (kit)

Item	Qty	Description
4	1	PMC bezel for mezzanine front panel, Zn die-cast or Al extrusion
7	1	EMC gasket (O-ring), Cho-Seal

Order Information


PMC mezzaninefront panel	Qty/PU	with EMC gasket	without EMC gasket
Material		Part no.	Part no.
Al extrusion, anodised, contact surfaces conductive	1	20835-598	–
Al extrusion, anodised, contact surfaces conductive	10	20835-889	20835-899
Zn die-cast, untreated	1	20835-890	–
Zn die-cast, untreated	10	20835-893	20835-896
Zinc die-cast, black, chromated	1	20835-922	–
Zinc die-cast, black, chromated	10	20835-924	20835-931
Zinc die-cast, chrome-plated, matt	1	20835-923	–
Zinc die-cast, chrome-plated, matt	10	20835-928	20835-929
Cheesehead screw M2.5 × 5 mm, PU 100 pieces			21100-624
EMC gasket O-ring, 1 piece (Standard Pack Quantity 10 pieces)			60835-021



For further information www.schroff.biz/oneclick
oneClick search code = Part no.

Front panels


FMC mezzanine front panels

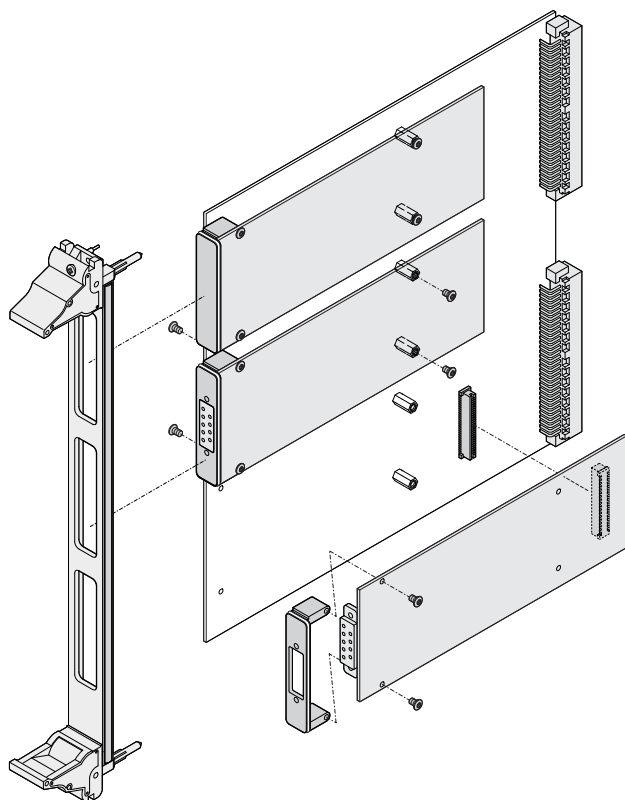

04615052

- FMC = FPGA mezzanine card
- For standard defined I/O mezzanine modules which connect to carrier cards
- For single 69.0 x 76.5 mm or double 139.0 x 76.5 mm modules
- In accordance with Vita 57.1 specification

FMC mezzanine front panel kit, shielded, with IEL handle

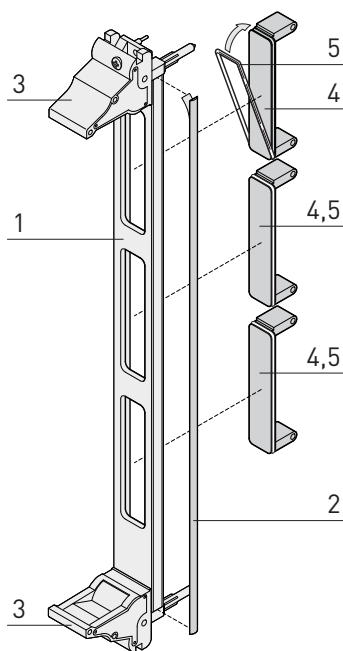

04615050

- 3 U or 6 U, 4 HP, U-shaped front panels with textile gasketing
- 1 or 3 FMC cutouts (depending on height)
- 1 or 2 IEL front handles (depending on height)
- EMC shielded, both the front panel and the FMC bezels

Delivery includes (assembled)


Item	Qty		Description
	3 U	6 U	
1	1	1	FMC front panel, U profile, Al, 4 HP, front anodized, rear conductive, 3 U has 1 cut out, 6 U has 3 cut outs
2	1	1	EMC textile gasket for front panel
3	1	2	IEL handle (handel, black, RAL 9005; button, light grey, RAL 7035)
4	1	3	FMC bezel for front panel cut outs
5	1	3	EMC gasket (O-ring)
6	1	1	Assembly kit

Order Information

Height	Part no.
U	
3	20836-253
6	20836-254
Accessories	
Spacer to mount PMC mezzanine boards	see page 7.15

Front panels

EMC bezel for FMC Mezzanine front panel cut-outs

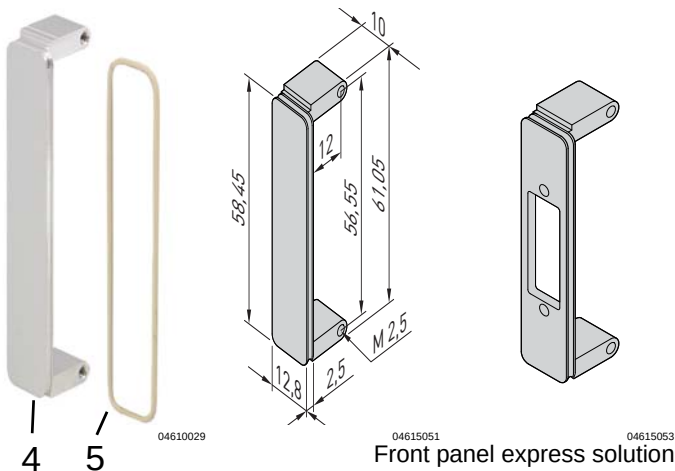


- FMC bezel is fitted into FMC Mezzanine front panel cut-outs
- Material, Al extrusion (anodised, contact surface conductive)
- Shielding for FMC bezels with an optional conductive O-ring, please order separately

Order Information

Description	Item	Qty/PU piece	Part no.
EMC bezel for FMC Mezzanine front panel cut outs	4	10	20835-849
Accessories			
EMC gasket for mezzanine front panel item 5 , O-ring, (VITA 57.1), 1 piece (standard pack quantity 10 pieces)			60835-077
Cheesehead screw M2.5 × 5 mm, PU 100 pieces			21100-624

Spacer to mount PMC and FMC mezzanine boards

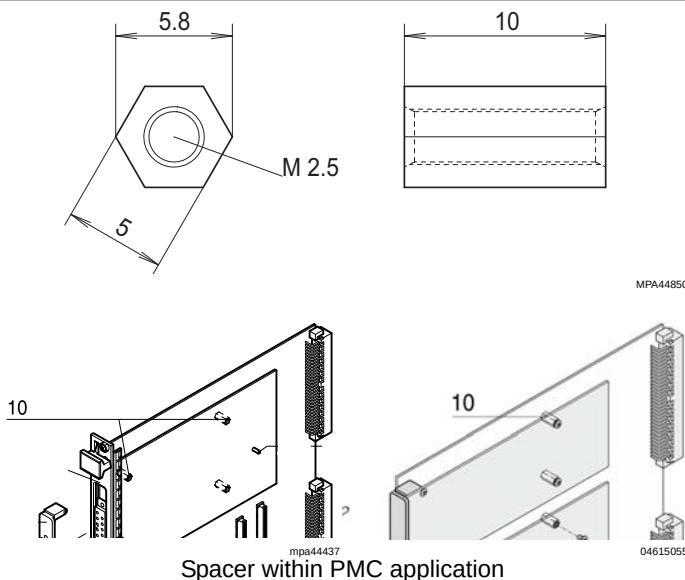


- To provide a standoff between mezzanine boards per the IEEE P1386 or VITA 57.1 specification and the carrier card

Order Information

Description	Item	Material	Qty	Part no.
Spacer	10	St, zinc-plated	1 piece (SPQ 10)	60897-278

Delivery is exclusively made in Standard Pack Quantity (SPQ): Please order at least 10 pieces or a multiple.
Pricing is per individual item.

Voltage keying/coding pin for PMC mezzanine boards

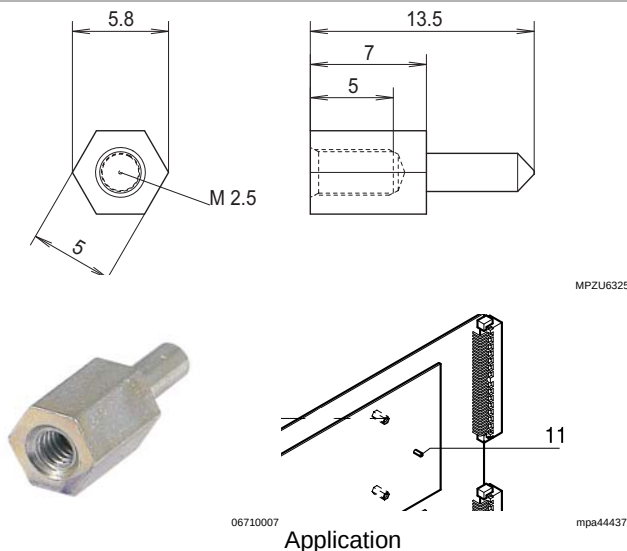

- To prevent accidental damage when fitting mezzanine boards, keying/coding pins are bolted to the VMEbus boards to distinguish between 3.3 V and 5 V operation. The mezzanine boards have a hole drilled in the appropriate position. The keying/coding pin thus ensures that only mezzanine boards with the same operating voltage can be inserted. For double-height euroboards 2 pieces are required.

Order Information

Description	Item	Material	Qty	Part no.
Keying/coding pin 5 V/3.3 V	11	St, zinc-plated	1 piece (SPQ 10)	60827-026

Delivery is exclusively made in Standard Pack Quantity (SPQ): Please order at least 10 pieces or a multiple.
Pricing is per individual item.

