


Deep groove ball bearings, single row, unsealed



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
25	52	15	14,8	7,8	0,335	28000	18000	0,13	6205 *

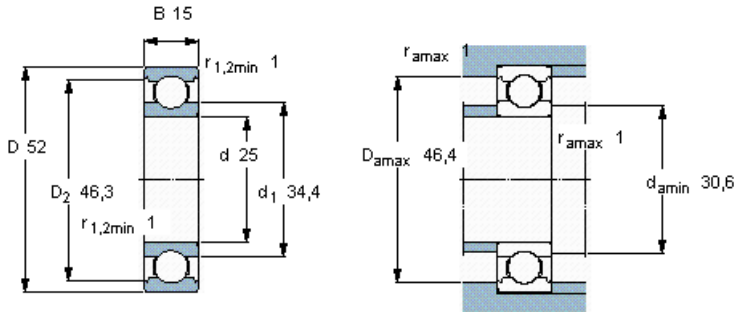

Calculation factors

k_r 0,025
 f_0 14