


Features

- **UL94HB flame rated Nylon 66 with metal powder.**
- **Color: Blue, other special color available request.**
- **One piece self-lock cable tie save the time and make effective for installation.**
- **Easy to thread.**
- **Excellent chemical resistance.**

RS PRO Metal Detectable Cable Ties

RS STOCK No.: 2812539

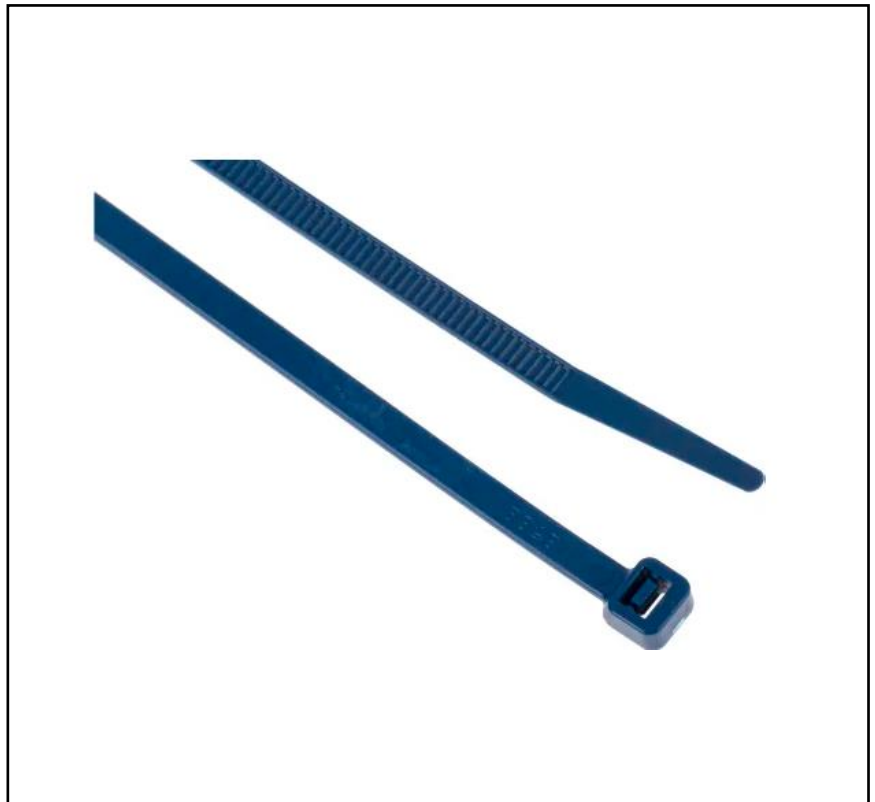

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

ATTRIBUTE 1


Introducing the range of RS PRO metal detectable cable ties. These cable ties have a unique blue colour that meets industry regulations so that it is easily identifiable to reduce contamination in production environments. In addition to this, the cable tie offers total diffusion of metal powder particles to ensure that every single part of the cable tie is detectable, even if it has been trimmed to size. The RS PRO metal detectable cable tie is ideal for use when installing cabling in factories, industrial and manufacturing plants, where there is a high risk of contamination.

General Specifications

Type	Metal Detectable
Colour	Blue
Material	PA66MP
Resistant to	Chemical resistance
Quantity	100

Mechanical Specifications

Length	100mm / 4"
Width	2.5mm / 0.1"
Min. Loop Tensile Strength(lbs/kgf/N)	14lbs / 6kgf / 60N
Maximum Bundle Dia.	22mm

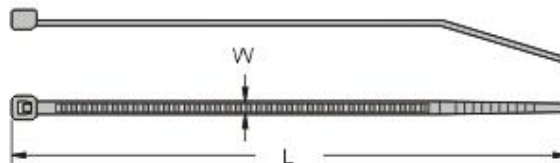

Approvals

Standards Met	RoHS, HF
---------------	----------

Similar Products

Stock No.	Brand	Product Name	Colour	Material	Length
172-1766	RS PRO	Metal Detectable Cable Ties	BLUE	PA66MP	150
172-1765	RS PRO	Metal Detectable Cable Ties	BLUE	PA66MP	200

