



ENGLISH

Datasheet


AC Axial Fan, 120 x 120 x 38mm, 187m/h, 24W, 120 V ac (OA4715 Series)

RS Stock number [619-6955](#)



RS Order Number	6196955	6196961
Model Number	OA4715-12TB	OA4715-23TB
Part Number	247315004	247615004
Nominal Voltage	120 VAC	230 VAC
Nominal Current	0.30A	0.23A
Rated Power	29/24W	28/24 W
Rated Speed (RPM)	3000	3000
Airflow (CFM)	110	110
Noise Level (dB)	43	43
Max. Static Pressure	0.37" H2O	0.37" H2O

Drawing(mm):

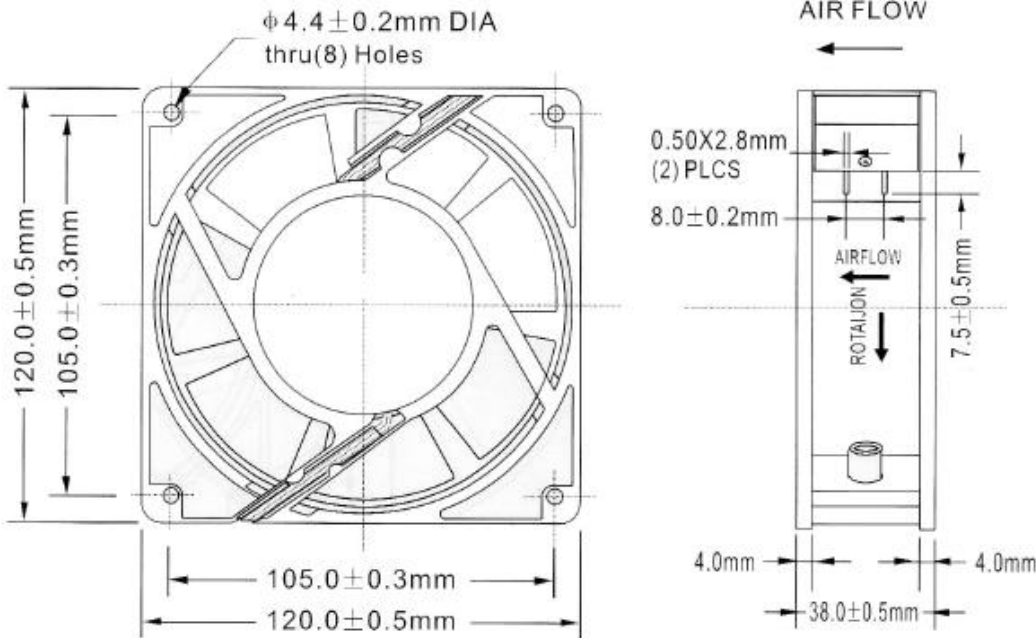

Specifications:

Frame:	Diecast Aluminium
Impeller:	PBT, UL94V-O plastic
Connection:	Terminals
Motor:	AC shaded pole, impedance and thermally protected
Bearing System:	Dual ball
Insulation Resistance:	>100M ohm between lead-wire and frame (500VDC)
Dielectric Strength:	1 min at 1500VAC, 50/60Hz
Operating Temp:	Ball bearing $-20^{\circ}\text{C} \sim +80^{\circ}\text{C}$
Life Expectancy:	Ball bearing 60,000 hours (L10 at 40C)