


Deep groove ball bearings, single row, unsealed

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
6	19	6	2,34	0,95	0,04	80000	50000	0,0084	626 *

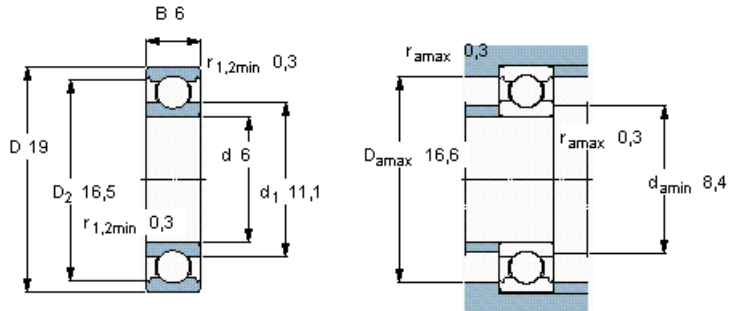

Calculation factors

$k_r = 0,025$

$f_0 = 13$