
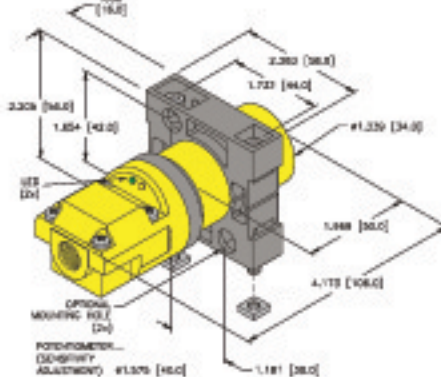


TURCK
Level Sensors - Capacitive

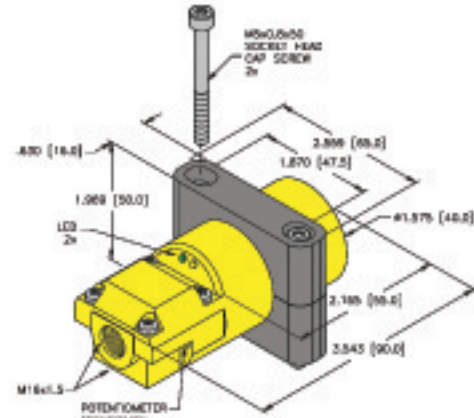

Housing Style	Part Number	ID Number	Features	Embeddable Range (mm)	Nonembed. Range (mm)	Output
34 mm - Embeddable, Terminal Chamber 	BC15-K34SR-VM4X2	M2502128	Comp. Outputs	15	23	4-Wire DC NPN
	BC15-K34SR-VP4X2	M2502129	Comp. Outputs	15	23	4-Wire DC PNP
	BC15-K34SR-FZ3X2	M2310009	Prog. Outputs	15	23	2-Wire AC
40 mm - Embeddable, Terminal Chamber 	BC20-K40SR-VM4X2 W/M16X1.5	M2510100	Comp. Outputs	20	30	4-Wire DC NPN
	BC20-K40SR-VP4X2 W/M16X1.5	M2510000	Comp. Outputs	20	30	4-Wire DC PNP
	BC20-K40SR-FZ3X2 W/M16X1.5	M2310300	Prog. Outputs	20	30	2-Wire AC

Voltage	Switching Freq. (Hz)	Operating Current (mA)	Operating Temp. (°C)	Protection Class	Housing	End Cap	Power LED	Output LED	Mating Cordset	Wiring Diagram #	Wiring Diagrams
10-65 VDC	100	≤200	-25 to +70	IP 67	PBT	ABS	GN	YE	----	1	Diagram 1
10-65 VDC	100	≤200	-25 to +70	IP 67	PBT	ABS	GN	YE	----	2	Diagram 2
20-250 VAC	20	≤500	-25 to +70	IP 67	PBT	ABS	GN	YE	----	3	Diagram 3
10-65 VDC	100	≤200	-25 to +70	IP 67	PBT	ABS	GN	YE	----	1	
10-65 VDC	100	≤200	-25 to +70	IP 67	PBT	ABS	GN	YE	----	2	
20-250 VAC	20	≤500	-25 to +70	IP 67	PBT	ABS	GN	YE	----	3	