


Data Specification Sheet

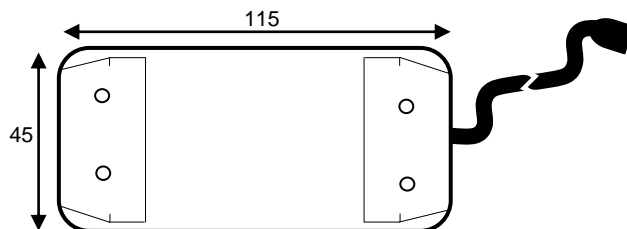

PLD23W 24W Dimmable Constant Current LED Driver

ML Accessories Code	PLD23W
Description	23W 600mA Dimmable Constant Current LED Driver for use with PL23LED
Input Voltage (V)	220-240V 50/60Hz
Secondary Voltage (V)	35 - 42V DC
Rated Current (Secondary) (A)	600mA
Rated Current (Primary) (A)	0.10A
Rated Load(W)	24Watts
PF	0.92
Driver Type	Constant Current
Dimmable	Yes – Trailing Edge
Standard Overall dimensions (mm)	(D)27mm (L)115mm (W)45mm
Colour	Orange/White
Isolation Class	Class II
IP	IP20
Recommended product location	Indoor in Free Air Space
Short Circuit Protection	Yes – Auto Reset
Thermal Protection	Yes – Single Shot Thermal Fuse
Overload Protection	Yes
Surge Protection	Yes
Power factor correction	Yes
Dimmable	No
Instruction sheet	Yes
Origin of manufacture	China
Main materials:	
• Body	Self Extinguishing Polycarbonate
Method of fix	2 X Screw
Input Connection	Terminal 1.5mm Max strain relief
Output Connection	Pre leaded for use with PL23LED
F mark	Yes
CE mark	Yes to current LV & EMC Directives
Quality Assurance System	Yes ISO 9001 QMS
Batch coding details on product	Yes
Certificate of Conformity	Yes
Manufactured in accordance to:	EN55015(EMC/Emitted RF) ,EN61547(EMC/Immunity) EN61000.3.2(EMC/Supply Harmonics) EN61347-2-7(Safety) SELV
Guarantee Period	1 Years
EAN	5055559189855

ML Accessories Ltd. reserves the right to withdraw, improve or modify any design without prior notification.
ML Accessories Ltd. cannot be held responsible for the incorrect application of any product.