


Verbatim LED GU10 8.5W 3000K 620lm 3000K Warm White 650 LM DIM



- GU10 Socket
- 220-240V
- 30,000 hours Lifetime
- Dimmable
- 90% Energy Saving
- Luminous Flux: 650 lm
- Equivalent to 86W incandescent bulb

Product Number	52310
General Data	
Lamp Socket	GU10
Electric Data	
Wattage (W)	8.5
Wattage Equivalent (W)	86
Voltage (V)	220-240
Dimmable	yes
Power Factor	≥0.7
Operating Frequency (Hz)	50/60
Geometric Data	
Length (mm)	56
Diameter (in mm)	50
Weight (g)	55
Photometric Data	
Luminous Flux (lm)	650
Luminous Flux 90° Cone (lm)	620
CRI	80
CCT (K)	3000
Luminous Intensity (cd)	1250
Beam Angle (°)	35
Luminous Efficacy (lm/W)	76
Lifetime (hrs)	30,000
Switching Cycle	100,000

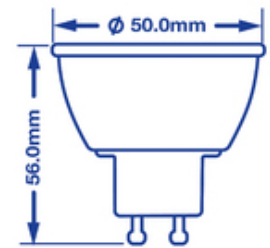

28/11/2014

Photometric Diagrams

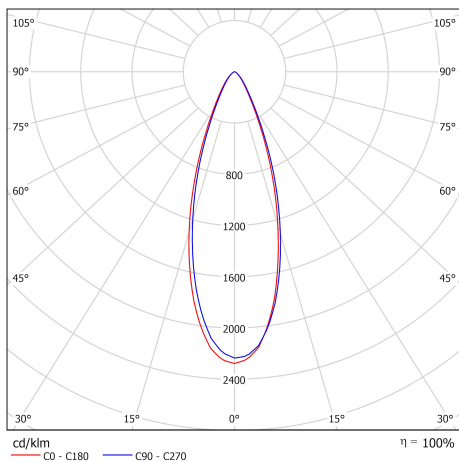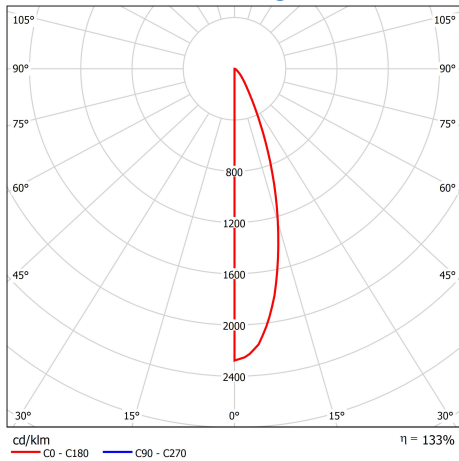


Distance [m]	Cone Diameter [m]	E(0°)	E(C90)	E(C0)	Illuminance [lx]
0.5	0.32	6079	17.9°	2583	2665
	0.30		16.9°		
1.0	0.65	1520	17.9°	646	666
	0.61		16.9°		
1.5	0.97	675	17.9°	287	296
	0.91		16.9°		
2.0	1.29	380	17.9°	161	167
	1.22		16.9°		
2.5	1.61	243	17.9°	103	107
	1.52		16.9°		
3.0	1.94	169	17.9°	72	74
	1.82		16.9°		

Distance [m] Cone Diameter [m] Illuminance [lx]

— C0 - C180 (Half-value Angle: 33.8°)
 — C90 - C270 (Half-value Angle: 35.8°)

Energy Rating

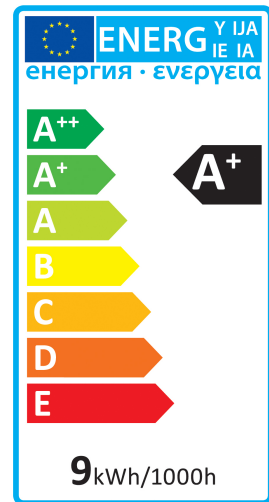

Technical Packaging Details

Barcode

023942523109

EAN 128

(02)00023942523109(37)10(91)814

EAN 14

50023942523104

Pack Dimensions(HxWxL)

H67 *W51*L51mm (mm)

MOQ

10

Carton Dimensions (HxWxL)

H97*W125 *L285mm (mm)

Cartons/Pallet

171

Layers/Pallet

9

Units/Pallet

1710

28/11/2014