




2142 T (MM)

HEXAGON ALLEN KEY WITH 2C-T-HANDLE

for in-hex screws

- With hanging hole
- GEDORE vanadium steel 61CrSiV5, chromated

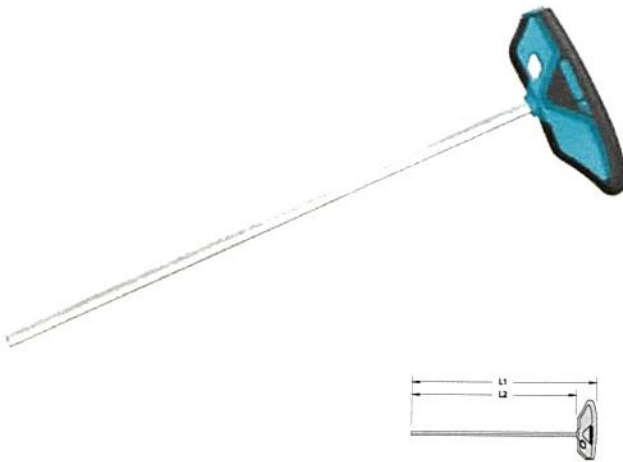


mm	L ₁	L ₂	mm	Code	No.
2	157	130	0.061	2647257	2142 T 2
2,5	187	160	0.091	2647265	2142 T 2,5
3	217	190	0.071	2647273	2142 T 3
4	248	210	0.080	2647281	2142 T 4
5	278	240	0.100	2647303	2142 T 5
6	308	270	0.140	2647311	2142 T 6
7	328	290	0.160	2681439	2142 T 7
8	348	310	0.221	2647338	2142 T 8
10	368	330	0.201	2647346	2142 T 10

DT 2142

HEXAGON ALLEN KEY WITH 2C-T-HANDLE

for in-hex screws

- With hanging hole
- With 2 hexagons, same size each end

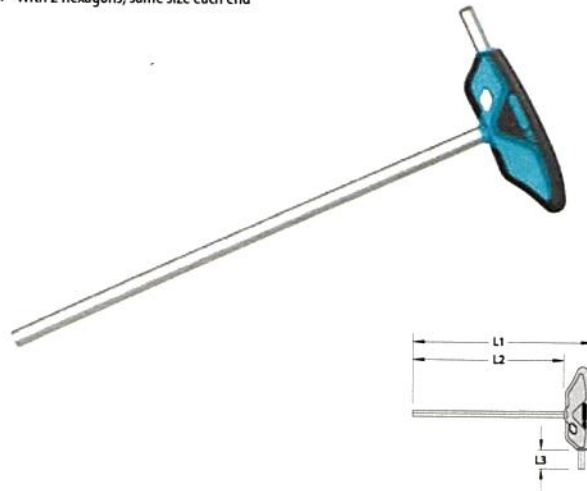


mm	L ₁	L ₂	L ₃	mm	Code	No.
2	112	85	12	0.091	2488914	DT 2142 2
2,5	132	105	12	0.071	2498596	DT 2142 2,5
3	152	125	12	0.040	2498618	DT 2142 3
4	178	140	16	0.080	2498626	DT 2142 4
5	198	160	18	0.100	2502631	DT 2142 5
6	218	180	21	0.120	2502658	DT 2142 6
7	228	190	24	0.251	2505487	DT 2142 7
8	243	205	26	0.180	2507447	DT 2142 8
10	258	220	28	0.280	2507471	DT 2142 10

2142 T (AF)

HEXAGON ALLEN KEY WITH 2C-T-HANDLE

for in-hex screws

- With hanging hole
- GEDORE vanadium steel 61CrSiV5, chromated

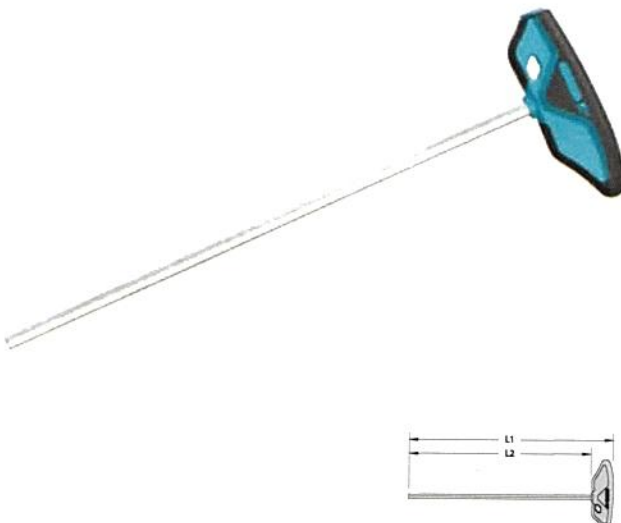


AF	L ₁	L ₂	mm	Code	No.
1/8	217	190	0.101	2647354	2142 T 1/8AF
5/32	248	210	0.121	2647362	2142 T 5/32AF
3/16	278	240	0.100	2647370	2142 T 3/16AF
1/4	308	270	0.140	2647389	2142 T 1/4AF
5/16	348	310	0.221	2647397	2142 T 5/16AF

2142 TX

WRENCH KEY WITH 2C-T-HANDLE for recessed TORX® screws

- With hanging hole
- Chrome-vanadium steel, blade chrome-plated, tip gun-metal finish
- TORX® = reg. trademark of Acument Intellectual Properties, LLC. USA

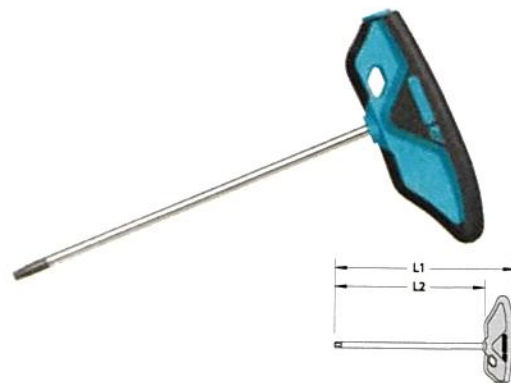

	 mm	 mm	L ₁	L ₂	 Code	No.
T5	M1,8	1,42	112	85	0.081 2509393	2142 TX T5
T6	M2	1,70	112	85	0.081 2511622	2142 TX T6
T7	M2,5	1,99	112	85	0.081 2511657	2142 TX T7
T8	M2,5	2,31	112	85	0.051 2513072	2142 TX T8
T9	M3	2,50	132	105	0.071 2513102	2142 TX T9
T10	M3 - M3,5	2,74	132	105	0.061 2513749	2142 TX T10
T15	M3,5 - M4	3,27	152	125	0.091 2516934	2142 TX T15
T20	M4 - M5	3,86	167	140	0.081 2519062	2142 TX T20
T25	M4,5 - M5	4,43	178	140	0.091 2519186	2142 TX T25
T27	M4,5 - M6	4,99	198	160	0.100 2521571	2142 TX T27
T30	M6 - M7	5,52	198	160	0.100 2521598	2142 TX T30
T40	M7 - M8	6,65	218	180	0.140 2521601	2142 TX T40
T45	M8 - M10	7,92	230	180	0.160 2521602	2142 TX T45