

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130111-0023](#)
Status: **Active**
Overview: [Stringlights](#)
Description: Pro-Yellow® Stringlight, 150W, 14/2 AWM with 2.43m Lead 10 Sockets with Guards, Overall Length 30.48m (100.0')

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

General

Product Family	Portable Lighting
Series	130111
NEMA Configuration	N/A
NEMA Rating	Rain Tight
Outlet	None
Overview	Stringlights
Product Literature Order No	987650-8055
Product Name	Pro-Yellow®
Type	String Lights
UPC	78678853637
Woodhead	Yes

Physical


Cord Length - Primary	2.43m (8.0')
Cord Length - Secondary	0.61m (2.0')
Depth	N/A
Duty	General
Guard Included	STR101
Guard Type	N/A
Height	N/A
Length	30.48m (100.0')
Material - Guard	Polypropylene
Mounting Style	Stringer
Net Weight	3.960/kg
Packaging Type	Carton
Socket Construction	Assembled

Electrical

Bulb Type	Incandescent
Cord Type - Primary	14/2
Lamp Type	A21
Lamp Wattage - Maximum	150W
Lumens	1500
On/Off Switch	No
Voltage (Fixture) - Maximum	120VAC 60 HZ

Material Info

Old Part Number	202SRL
-----------------	--------

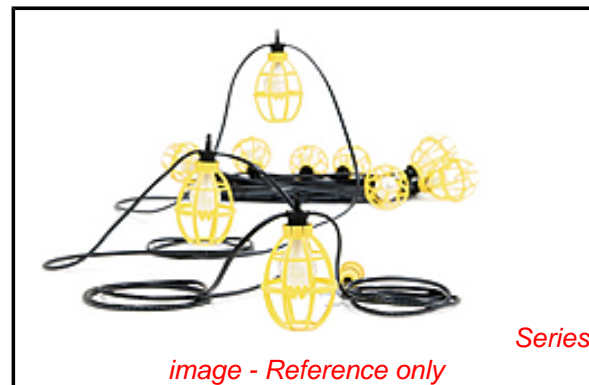

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Not Reviewed**
**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130111Series