

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130299-0400](#)
Status: **Active**
Overview: Brad® Micro-Change® (M12) Connectors
Description: Brad® Micro-Change® (M12) Harsh-Duty Receptacle, 5 Pole, A-Code, Straight

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-130299-001 \(PDF\)](#)

General

Product Family	Industrial Receptacles
Series	130299
IP Rating	IP67
Overview	Brad® Micro-Change® (M12) Connectors
Product Name	Micro-Change® (M12)
Type	PCB Mount
UPC	78172513055

Physical

Coupling Type	Internal Thread
Gender	Female
Keyway	A-coded
Length	N/A
Material - Component	Nickel-plated Zinc Die-Cast
Mounting Thread Size	M12 x 1.0
Orientation	Straight
Panel Mount	Back, Front
Poles	5
Temperature Range - Operating	-40°C to +85°C
Wire Size AWG	N/A
Wire/Cable Type	N/A


Electrical

Current - Maximum per Contact	4A
Voltage - Maximum	250V AC/DC

Material Info

Reference - Drawing Numbers

Product Specification	PS-130299-001
Sales Drawing	SD-130299-008

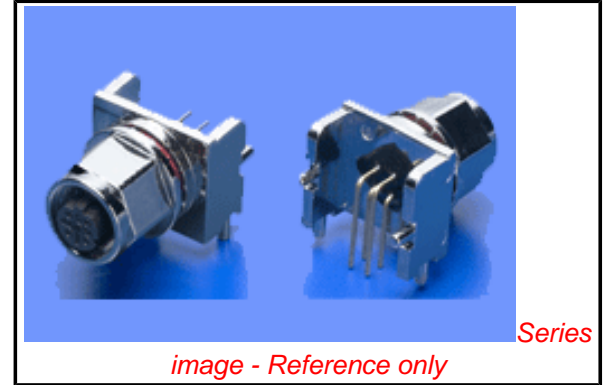

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Not Reviewed**
**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[130299Series](#)

Mates With

Male A-Code Cable Assembly