

# HAND HELD CASES

## 2900 Series Sloped Cases

Scratch resistant desktop or hand-held enclosures with recess in lid. Ideal for mobile electronic that require a battery compartment


- Lid, base and battery lid moulded in high grade ABS
- Lid mounted by four M3 machine screws
- Angled LCD area
- Sliding battery compartment lid
- Recess in lid for membrane keypads or overlays



### SPECIFICATION

Materials	Lid, base and battery lid in high grade ABS
Operating Temperature	Resistant to temperatures of up to 85°C
Protection class	IP54
Standard colours	Grey or Black. Ivory to order
Standard unit includes	Lid & base Battery compartment lid 4 x M3 machine screws 4 x rubber feet

BLACK	GREY	LENGTH	WIDTH	HEIGHT
BIM2901-BLK/BLK	BIM2901-GY/GY	165mm	87mm	24mm

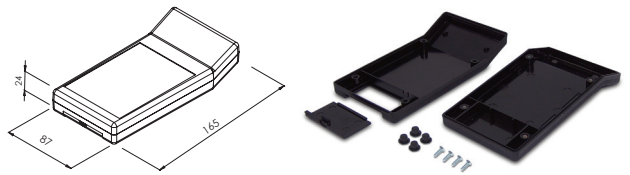

## 2910 Series Mobile Cases

Functional hand-held ABS cases with recessed lid and a battery compartment.

- Lid and base moulded in high grade ABS
- Lid mounted by four M3 machine screws
- Snap-on battery compartment lid
- Battery compartment for two AA, AAA or one PP3 battery
- PCB pillars in base
- Recess in lid for membrane keypads or overlays



### SPECIFICATION

Materials	Lid, base and battery lid in high grade ABS
Operating Temperature	Resistant to temperatures of up to 85°C
Protection class	IP54
Standard colours	Light grey similar to RAL 7035 or black similar to RAL 9004
Standard unit includes	Lid & base Battery compartment lid 4 x M3 machine screws 4 x self-tapping PCB screws

BLACK	GREY	LENGTH	WIDTH	HEIGHT
RERB551-BLK	RERB551-LG	105mm	61mm	28mm
RERB552-BLK	RERB552-LG	145mm	80mm	34mm

