




Order Product and Get Support

- U.S. Authorized Distributors
- Global Sales & Service
- N. American Sales Reps
- Distributor Inventory
- Technical Assistance
- White Papers
- Literature Request
- Test and Measurement Catalog
- RoHS Product List
- Customer Feedback

1TP66-1

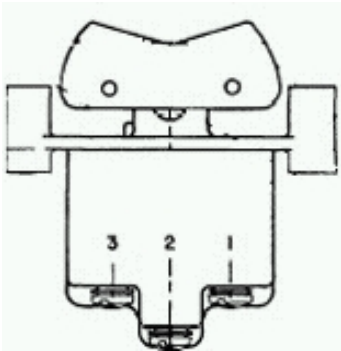

Actual product appearance may vary.

TP Series Rocker Switch, 1 pole, 3 position, Screw terminal, Flush Panel Mounting

Features

Environmentally sealed  
Two and three-position pushbutton action  
Various button colors  
1, 2, and 4-pole circuitry  
Flush panel and above panel mountings  
Temperature range: -54 ° C to +71 ° C [-65 ° F to +160 ° F]  
UL recognized, CSA certified  
CE approved

Potential Applications

Industrial machinery and equipment  
Military and commercial aviation  
Marine applications  
Construction equipment  
Test instruments  
Agricultural machinery  
Process control  
Medical instrumentation

Description

MICRO SWITCH™ TP Rocker switches may be mounted flush with panel for a low-button profile or above panel for a distinct button appearance. Buttons measure 22,1 mm x 37,1 mm [.87 in x 1.46 in]. They are removable and interchangeable, and come in transparent plastic, translucent plastic, and six colors of opaque plastic. Switches without buttons are also available, as well as separate buttons.

Supporting Documentation

- Accessory: Rocker Operator
- Engineering Drawing

| Product Specifications                |                                                                                                           |
|---------------------------------------|-----------------------------------------------------------------------------------------------------------|
| Circuitry/Operating action            | <div>Keyway Position</div> <div>Center Position</div> <div>Opposite Keyway Position</div>                 |
| Product Type                          | MICRO SWITCH™ Rocker                                                                                      |
| Ampere/Voltage Range (Resistive Load) | 0.75 A at 115 Vdc,0.5 A at 250 Vdc,0.5 A to 20 A at 0.5 Vdc to 28 Vdc,0.5 A to 15 A at 0.5 Vac to 277 Vac |
| Circuitry                             | SPDT                                                                                                      |
| Action                                | 3 position                                                                                                |
| Mounting                              | Flush Panel                                                                                               |
| Termination                           | Screw                                                                                                     |
| Button Type                           | Transparent                                                                                               |
| UL/CSA Rating Code                    | L191: 15 A - 125, 250, 277 Vac; 1/2 Hp - 125 Vac; 1 Hp - 250, 277 Vac; 5 A - 120 Vac "L"                  |
| Comment                               | Button furnished unassembled                                                                              |
| Availability                          | Global                                                                                                    |
| UNSPSC Code                           | 302119                                                                                                    |
| UNSPSC Commodity                      | 302119 Switches and controls and relays                                                                   |
| Series Name                           | TP                                                                                                        |

My Links

- Login to iCOM
- Login as Rep/AD
- Login as Guest
- Login to Digital University

Keyword Search

Search for product and support information.

All Sensing and Control

Product Search

Part number search:

Use (\*) to expand search

Specification Search