



VDE 8250 H

VDE HEAVY DUTY COMBINATION PLIERS

with VDE insulating sleeves

- For heavy continuous use
- Good lever action for easy cutting
- Induction-hardened precision cutting edges, hardness 62 - 64 HRC
- For flat and round material
- To cut all wire types including piano wire, 1.6 mm
- GEDORE special hardened and tempered steel, chrome-plated
- Handles with VDE insulating sleeves up to 1000 V, acc. to EN 60900/IEC 60900



1000 V



L	L ₃	W ₃	W ₄	T ₁		Code	No.
160	35.0	22.8	5.8	10.4	0.228	1550942	VDE 8250-160 H
180	38.5	25.6	6.5	11.0	0.288	1550950	VDE 8250-180 H
200	39.5	27.0	6.5	12.4	0.369	1550969	VDE 8250-200 H

VDE 8314 H

VDE SIDE CUTTER with VDE insulating sleeves

- With slender head - ideal for confined spaces
- Induction-hardened precision cutting edges, hardness 63 - 65 HRC
- For medium-hard wire, 1.6 mm
- GEDORE special hardened and tempered steel, chrome-plated
- Handles with VDE insulating sleeves up to 1000 V, acc. to EN 60900/IEC 60900





1000 V



L	L ₃	W ₃	T ₁	Ø		Code	No.
140	18.5	18.5	9.5	1.6	0.177	1552155	VDE 8314-140 H
160	19.0	22.0	10.0	1.6	0.231	1552163	VDE 8314-160 H

1500 CT1-VDE 142

110

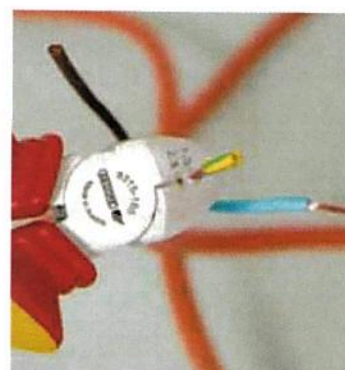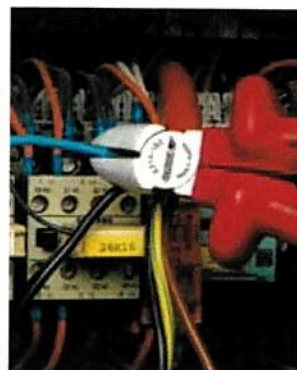

VDE 8314

VDE SIDE CUTTER with VDE dipped insulation

- With slender head - ideal for confined spaces
- Induction-hardened precision cutting edges, hardness 63 - 65 HRC
- For medium-hard wire, 1.6 mm
- GEDORE special hardened and tempered steel, chrome-plated
- Handles with VDE dipped insulation up to 1000 V, acc. to EN 60900/IEC 60900, two-ply Check-Tool insulation



1000 V



L	L ₃	W ₃	T ₁	Ø		Code	No.
140	18.5	18.5	9.5	1.6	0.199	6743540	VDE 8314-140

VDE 8315 H

VDE ELECTRICIANS' SIDE CUTTER with VDE insulating sleeves

- Double-function electricians' side cutters for cutting and wire stripping
- Stripping holes for single- or multi-core conductors 1.5 and 2.5 mm²
- Induction-hardened precision cutting edges
- GEDORE special hardened and tempered steel, chrome-plated
- Handles with VDE insulating sleeves up to 1000 V, acc. to EN 60900/IEC 60900



1000 V

