


Tool Header Informations

G600

Countersink, Extra Long - 90°

NEW
2013.05

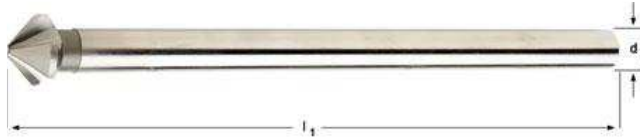

- 1.1
- 1.2
- 1.3
- 1.4
- 1.5
- 1.6
- 2.1
- 2.2
- 2.3
- 3.1
- 3.2
- 3.3
- 6.1
- 6.2
- 6.3
- 6.4
- 7.1
- 7.2
- 7.3
- 7.4

max d mm	min d	l ₁ mm	d ₂ Øh ₉ mm	z	e-Code	GBP
6.3	1.3	154	5	3	G6006.3	71.00
8.3	1.8	155	6	3	G6008.3	74.60
10.4	2.2	157	6	3	G60010.4	85.60
12.4	2.5	158	8	3	G60012.4	96.50
15.0	2.8	159	10	3	G60015.0	95.30
16.5	2.8	161	10	3	G60016.5	107.00
20.5	3.0	164	10	3	G60020.5	145.00
25.0	3.2	168	10	3	G60025.0	210.00