


# Datasheet

## RS Crimp Tab Terminal, 6.35 x 0.8mm, 16 → 14 AWG Tin Plated

RS Stock number [488-1279](#)

### Dimensions (mm)

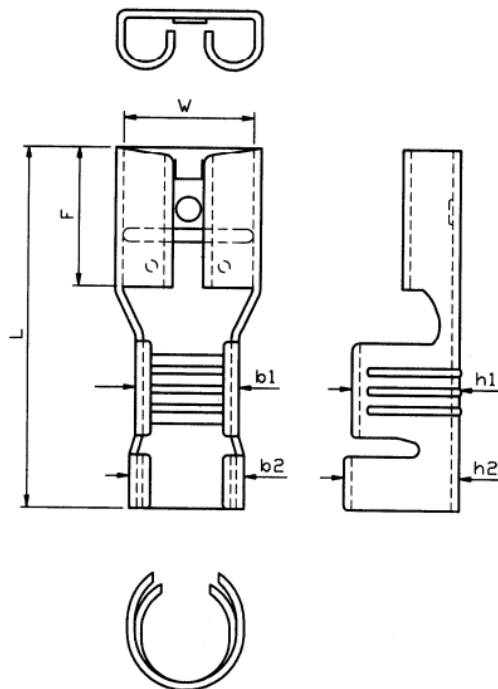

Tolerance/ Item	NEMA TAB ("d2)	W $\pm$ 0.2	F $\pm$ 0.3	L $\pm$ 1.0	B1 $\pm$ 0.5	B2 $\pm$ 0.5	H1 $\pm$ 0.5	H2 $\pm$ 0.5
Size	.032*250) (0.8*6.35)	6.3	8.0	20.0	3.0	4.8	3.2	4.5

### Specifications

- Wire Range: 16-14 A.W.G (0.5-1mm<sup>2</sup>)
- Maximum Current: 15AMP
- Material: Brass