


Number of contacts

50–68

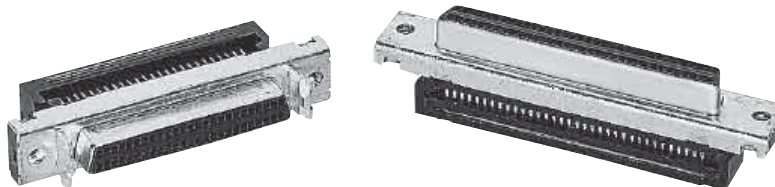

Female connectors for IDC flat cable, straight

har-mik

Identification

No. of contacts

Part No.

Female panel connectors
with insulation displacement
termination

for IDC flat cable pitch 0.635 mm
AWG 30

50
68


with latch system

60 04 050 5343
60 04 068 5343

with screw lock system

60 04 050 5344
60 04 068 5344


Dimensions for connectors
with latch system

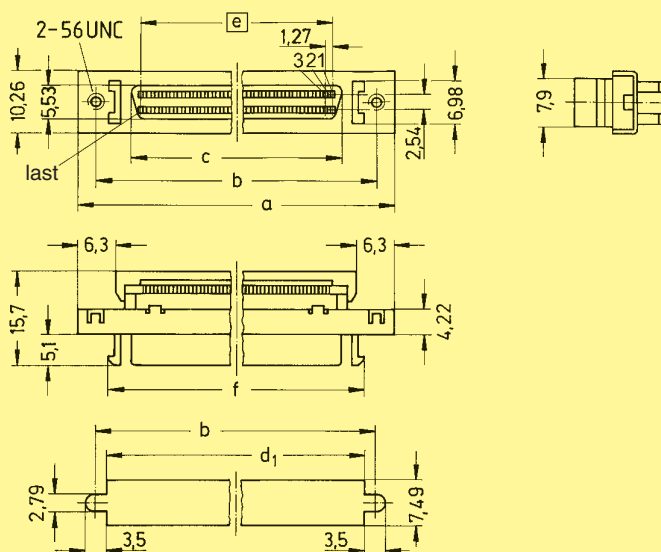

	a	b	c	d ₁	d ₂	e	f
50	52.45	46.48	34.70	42.80	42.30	30.48	42.30
68	63.88	57.91	46.13	54.23	53.72	41.91	53.72

Panel cut out

Dimensions for connectors
with screw lock system

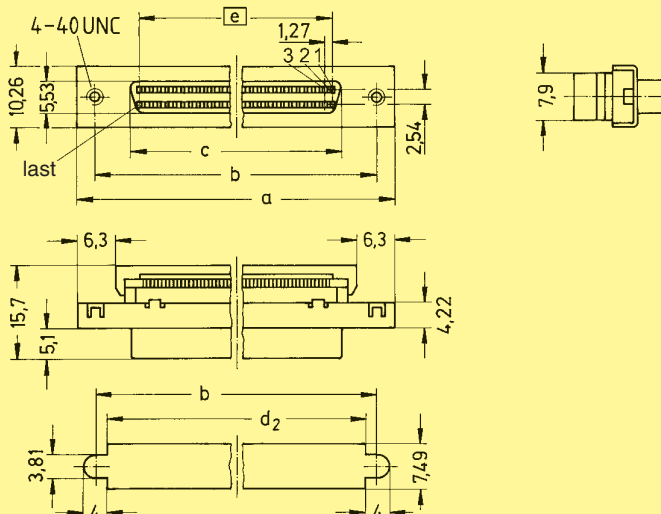

Panel cut out

Dimensions in mm