

Einzelspannzange

Single-Collet Plier

GRIP-ESZ...


Einzelspannzange zur schnellen und sicheren Kontaktierung von Schraubbolzen M4, M5 oder M6, z.B. an Motorenanschlüssen (Einstecktiefe 3 – 6 mm). Starre Ø 4 mm-Buchse im Drückerteil, geeignet zur Aufnahme federnder Ø 4 mm-Stecker mit starrer Isolierhülse oder als Leitungsabgang mit axialem Ø 4 mm-Lamellenstecker und starrer Isolierhülse. Gewindeeinsätze sind auswechselbar und separat erhältlich. Die Stromstärke ist abhängig vom Gewindeeinsatz.

GRIP-ESZ...



GRIP-ESZ...

Single-collet plier for fast and safe contacting to M4, M5 or M6 threaded bolts, for example on motor connections (contact depth 3 to 6 mm). Fixed Ø 4 mm socket in the pressure section, to fit spring-loaded Ø 4 mm plugs with rigid insulating sleeve or as a lead outlet with in-line Ø 4 mm Multilam plug and rigid insulating sleeve. Thread inserts are replaceable and available separately. The current depends on the thread insert.

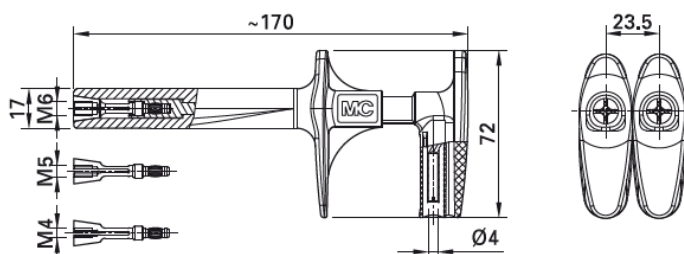


Typ Type	Bestell-Nr. Order No.	Bemessungsspannung/-strom Rated voltage/current	Zangeneinsatz Plier insert	Gewinde Thread	Längen L [cm] Lead lengths L [cm]	Farben Colors
GRIP-ESZ5	66.9447-21	1000 V, CAT IV / 30 A	Z5	M5	–	CE 21

Z5/M5



Z5	10.0805	30 A	Zangeneinsatz/Plier insert	M5
----	---------	------	----------------------------	----

 

Beilagezettel **RZ112**
www.multi-contact.com



RZ Sheet **RZ112**
www.multi-contact.com