


925367-6 -- 1 of 1 products

AMPMODU
Locking Clip, Mod. IV and Short Point Products

General **INFO**
Sales **INFO**
Customer Drawings **SPECIFICATIONS**

Ohne Verriegelung

Without Strain

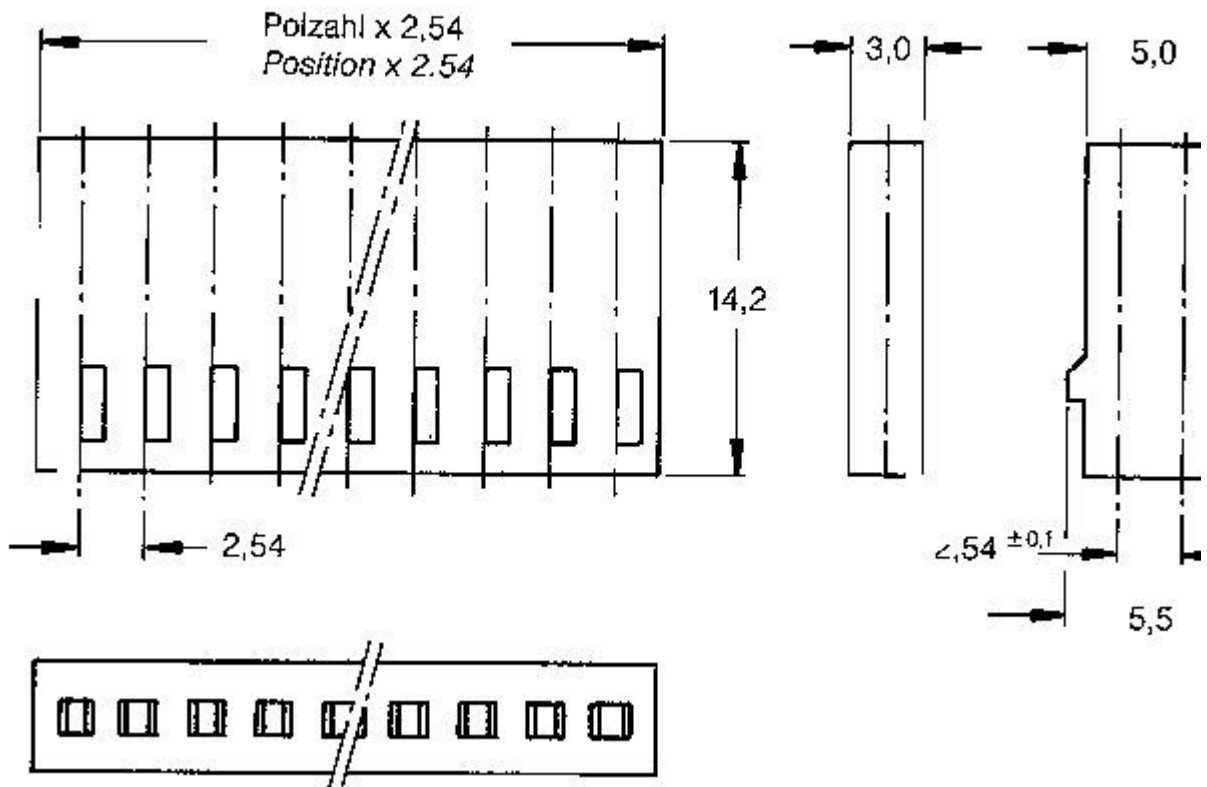

Line art represents typical product only.

Searchable Features:

# of Positions	12
# of Rows	Dual
Centerline Spacing	.100 x .100 [2.54 x 2.54] in. [mm]
Housing Configuration	Both Ends Closed
Contact Type	Mod IV, Mod V
Mating Polarization	No
Mating Connector Lock	Without
Strain Relief	Without
Keyed	No

Other Properties:

Housing Material	Nylon
Housing Flammability Rating	UL 94-HB
Housing Color	Green

[[Main Menu](#) | [Help](#) | [Families](#) | [Registration](#) | [Feedback](#)]
[Top of Page](#)