



ENGLISH

Datasheet

## **RS Pro Midget Flange Filament Indicator Lamp, Clear, 48 V, 25 mA, 2500h**

RS Stock No: **104-547**

### **Product Details**

RS Pro midget flange filament indicator lamp comes with clear lens and T1-3/4 incandescent bulbs. It has a voltage rating of 48 V, current rating of 25 mA. The lamp has 2500 h life.

### **Features and Benefits**


- Voltage rating of 48 V
- Current rating of 25 mA
- 2500 hours lifetime

**Specifications:**

Current Rating	25 mA
Diameter	5.84 mm
Lamp Base	Midget Flange
Lamp Size	T1 3/4
Length	16.1 mm
Lens Colour	Clear
Life Hours	2500 h
Luminosity	4 lm
Voltage Rating	48 V

RS Stock No.	104547
--------------	--------

*DRAWING - I*

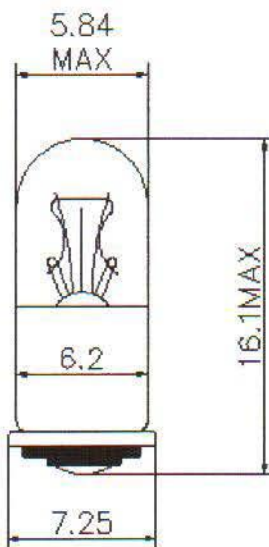

Unit : mm

1. Structure	Bulb Type	T1 3/4Clear
	Bulb Diameter	Ø5.84Max.
	Length	16.1Max
	Base Type	M.F.
2. Design Characteristics	Voltage	48V
	Amperage	25mA±10%
	Filament Type	Vacuum type
	Luminous Flux	4.0Lm±20%
	Life Hours	2,500Hrs