


Deep groove ball bearings, single row, unsealed

Principal dimensions			Basic load ratings		Fatigue load limit	Speed ratings		Mass	Designation
			dynamic	static		Reference speed	Limiting speed		
d	D	B	C	C ₀	P _u				* - SKF Explorer bearing
mm			kN		kN	r/min		kg	-
40	68	15	17,8	11,6	0,49	22000	14000	0,19	6008 *

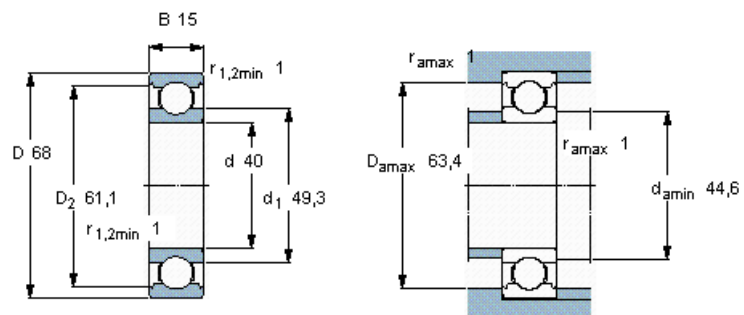

Calculation factors

 $k_r = 0,025$ $f_0 = 15$